

RA MMCX Plug to RA SMB Plug Cable RG316 Coax in 60 Inch

Electrical Specifications

Description	Min	Typ	Max	Units
Frequency Range	DC		3	GHz
Velocity of Propagation		70		%
Capacitance		32 [104.99]		pF/ft [pF/m]

Mechanical Specifications

Cable Assembly

Length* 60 in [152.4 cm]

Weight 0.068 lbs [30.84 g]

Cable

Cable Type

RG-316

Impedance

50 Ohms

Inner Conductor Type

Solid

Inner Conductor Material and Plating

Copper, Silver

Dielectric Type

PTFE

Number of Shields

1

Shield Layer 1

Silver Plated Copper Tape

Shield Layer 2

Silver Plated Copper Braid

Jacket Material

FEP, Black

Jacket Diameter

0.098 in [2.49 mm]

Connectors

Description	Connector 1	Connector 2
Type	MMCX Plug	SMB Plug
Impedance	50 Ohms	50 Ohms
Contact Material & Plating	Brass, Gold	Beryllium Copper, Gold
Contact Plating Spec.		30μ in. minimum
Dielectric Type	Teflon	Teflon
Body Material & Plating	Brass, Gold	Brass, Gold
Body Plating Spec.		3μ in. minimum

Mechanical Specification Notes:

*All cable assemblies have a length tolerance of 1.5% or $\pm 3/8"$, whichever is greater.

Environmental Specifications

Temperature

Operating Range -65 to +165 deg C

Compliance Certifications (see [product page](#) for current document)

Plotted and Other Data

Notes:



Configuration:

- MMCX Plug Right Angle
- SMB Plug Right Angle
- RG-316

Fairview Microwave
1130 Junction Dr. #100
Allen, TX 75013
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

How to Order

Part Number Configuration:

FMC1926315 - xx uu

_____ cm = Centimeters
 _____ <blank> = Inches
 _____ Length


Example: FMC1926315-12 = 12 inches long cable
 FMC1926315-100cm = 100 cm long cable

RA MMCX Plug to RA SMB Plug Cable RG316 Coax in 60 Inch from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [RA MMCX Plug to RA SMB Plug Cable RG316 Coax in 60 Inch FMC1926315-60](https://www.fairviewmicrowave.com/ra-mmcx-male-ra-smb-plug-cable-rg316-coax-fmc1926315-60-p.aspx)

URL: <https://www.fairviewmicrowave.com/ra-mmcx-male-ra-smb-plug-cable-rg316-coax-fmc1926315-60-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

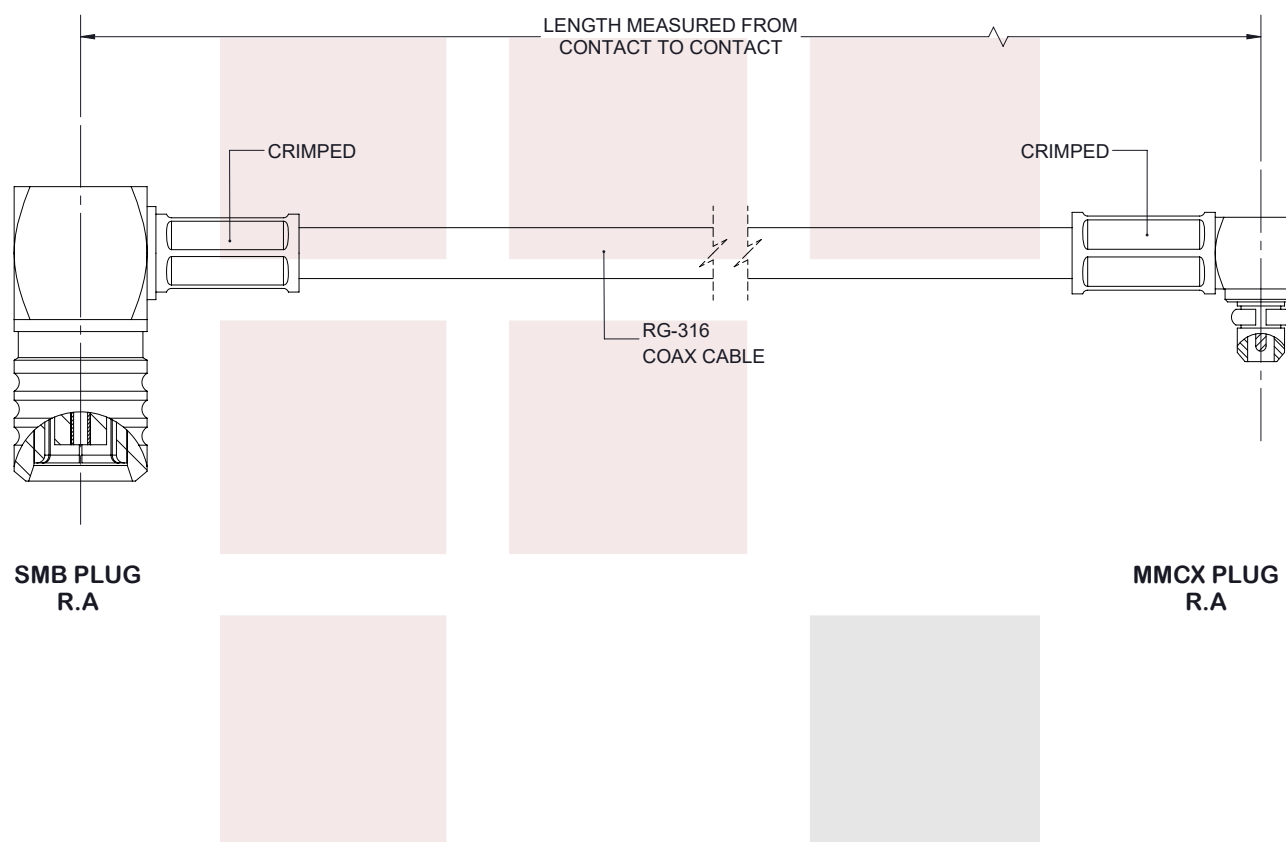

STANDARD TOLERANCES

.X ±0.2
.XX ±0.01
.XXX ±0.005

*STANDARD TOLERANCES APPLY
ONLY TO DIMENSIONS IN INCHES

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

NOTES:

1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN INCHES [mm].

TITLE

RA MMCX Plug to RA SMB Plug Cable RG316 Coax in
60 Inch

DWG NO

FMC1926315

CAGE CODE

3FKR5

CAD FILE

103017

SHEET

1 OF 1

SCALE

N/A

SIZE

A 7361