

1.85mm Male to 1.85mm Male Cable RG405 Coax in 24 Inch

Electrical Specifications

Description	Min	Typ	Max	Units
Frequency Range	DC		40	GHz
VSWR			1.55:1	

Mechanical Specifications

Cable Assembly

Length	24 in [609.6 mm]
Diameter	0.086 in [2.18 mm]

Cable

Cable Type	RG-405
Impedance	50 Ohms
Inner Conductor Type	Solid
Inner Conductor Material and Plating	Copper Clad Steel, Silver
Dielectric Type	PTFE
Number of Shields	1
Shield Layer 1	Copper

Connectors

Description	Connector 1	Connector 2
Type	1.85mm Male	1.85mm Male
Impedance	50 Ohms	50 Ohms
Contact Material & Plating	Beryllium Copper, Gold	Beryllium Copper, Gold
Contact Plating Spec.	MIL-G-45204, Type II, Class 1	MIL-G-45204, Type II, Class 1
Coupling Nut Material & Plating	Passivated Stainless Steel	Passivated Stainless Steel
Hex Size	5/16 in.	5/16 in.
Torque	8 in-lbs [0.9 Nm]	8 in-lbs [0.9 Nm]
Body Material & Plating	Stainless Steel, Gold	Stainless Steel, Gold
Body Plating Spec.	MILG45204, Type II, Class 1	MIL-G-45204, Type II, Class 1

Compliance Certifications (visit www.FairviewMicrowave.com for current document)

Plotted and Other Data

Notes:




Configuration:

- 1.85mm Male
- 1.85mm Male
- RG-405

Fairview Microwave
1130 Junction Dr. #100
Allen, TX 75013
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

Typical Performance Data

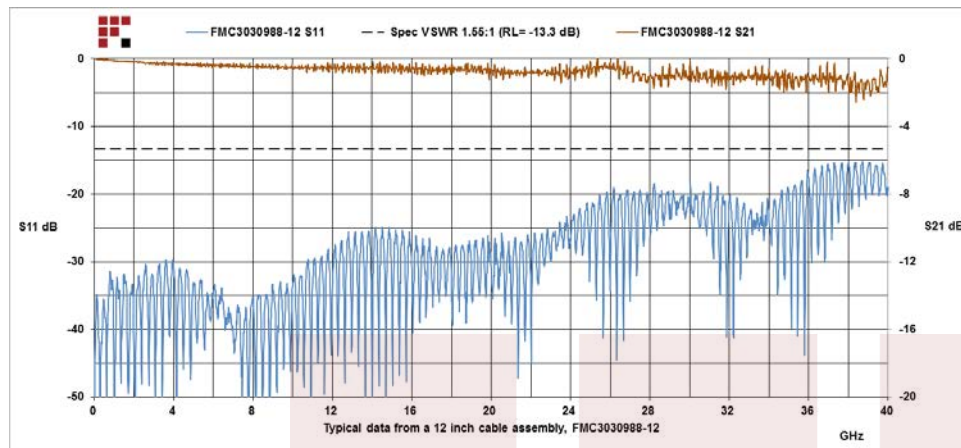

How to Order

Part Number Configuration:

FMC3030988 - xx uu

cm = Centimeters
<blank> = Inches
Length


Example: FMC3030988-12 = 12 inches long cable
FMC3030988-100cm = 100 cm long cable

1.85mm Male to 1.85mm Male Cable RG405 Coax in 24 Inch from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [1.85mm Male to 1.85mm Male Cable RG405 Coax in 24 Inch FMC3030988-24](http://www.fairviewmicrowave.com/1.85mm-male-1.85mm-male-cable-rg405u-coax-fmc3030988-24-p.aspx)

URL: <http://www.fairviewmicrowave.com/1.85mm-male-1.85mm-male-cable-rg405u-coax-fmc3030988-24-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

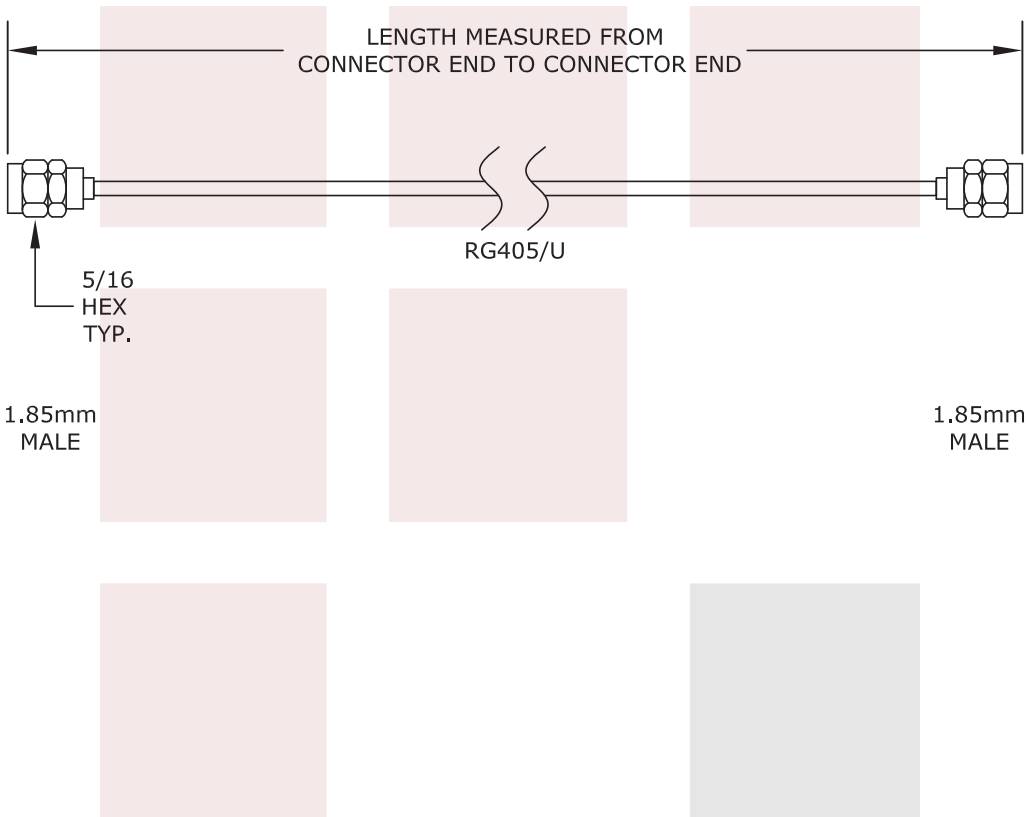

FAIRVIEW MICROWAVE INC. ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM		NOTES: 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL. 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME. 3. DIMENSIONS ARE IN INCHES [mm].			
TITLE 1.85mm Male to 1.85mm Male Cable RG405 Coax in 24 Inch	DWG NO FMC3030988		CAGE CODE 3FKR5		
	CAD FILE 061215	SHEET	SCALE N/A	SIZE A	2233