

# SMA FORMABLE SEMIRIGID CABLES 26.5GHZ

## RF085TM-XX


### SPECIFICATIONS

CABLE ASSEMBLY:  
VSWR: 1.4:1 MAX @ 26.5GHZ  
VSWR TESTED 100%

RAW CABLE: (BELDEN 1671A OR EQ)  
LOSS (EXCLUDING CONNECTORS)  
@ 1GHZ: 0.15 DB/FT  
@10GHZ: 0.8 DB/FT  
@18GHZ: 1.2 DB/FT  
@26.5GHZ 1.8 DB/FT

OUTER SHIELD DIAMETER: .086"


CONNECTORS:  
BODY: PASSIVATED STAINLESS STEEL  
CONTACTS Au PLATING MIL-G-45204

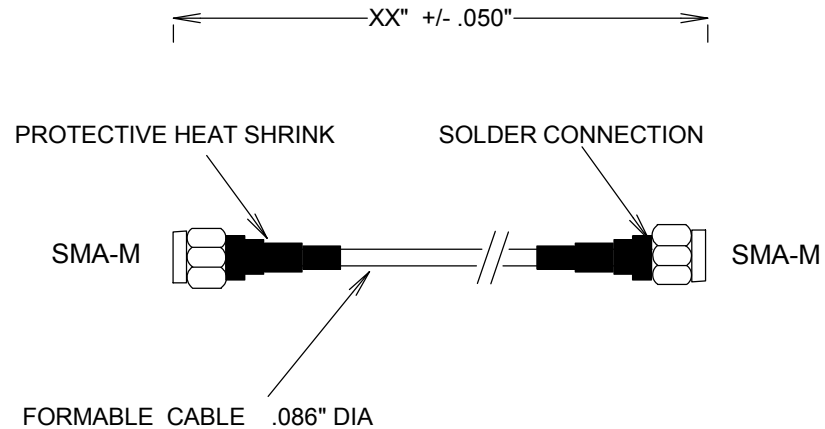

VSWR SWEEPED ON 100% OF ASSEMBLIES

THESE CABLES CAN BE FORMED BY HAND;  
THEY RETAIN THEIR SHAPE UPON FORMING  
THESE CABLES ARE NOT FLEXABLE

#### MEASUREMENTS BELOW ARE TYPICAL

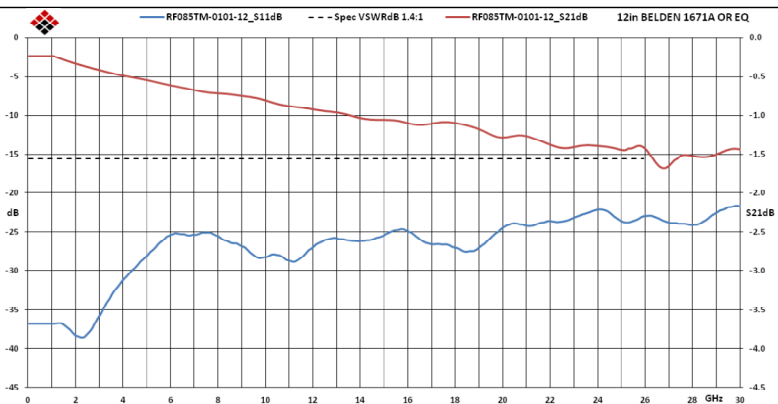

ALL DIMENSIONS IN inches(MM) Typical

## FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

### SMA FORMABLE SEMIRIGID CABLES 26.5GHZ

SIZE

**A**

CAGE CODE

3FKR5

DWG NO

**RF085TM-XX**

REV

**A**

SCALE

SHEET