



Straight Plug—For Flexible Cable

Figure 1
(Crimp type, shown with
supplied heat-shrink tubing)


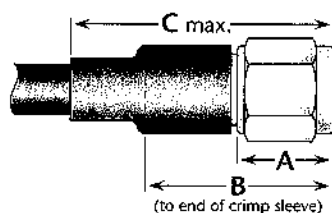



Figure 2
(Clamp type)

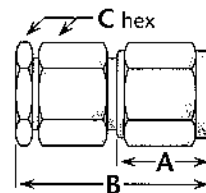

Cable Group	Figure	Dimensions			Plating		Delta P/N	Assembly Procedure/ Trim Code
		A	B	C	Body	Contact		
5	1	.330	.70	1.187	Gold	Gold	1303-017-G000	K/02
5	1	.330	.70	1.187	Passivated	Gold	1303-017-K000	K/02
6	1	.330	.70	1.187	Gold	Gold	1303-013-G000	K/02
6	1	.330	.70	1.187	Passivated	Gold	1303-013-K000-2	K/02
9	1	.330	.70	1.187	Gold	Gold	1303-036-G000	K/02
9	1	.330	.70	1.187	Passivated	Gold	1303-036-K000	K/02
10	1	.330	.70	1.187	Gold	Gold	1303-100-G000-2	K/02
10	1	.330	.70	1.187	Passivated	Gold	1303-100-K000-2	K/02
5, 6	2	.330	.75	.312	Gold	Gold (C)	1301-015-G005	***
5, 6	2	.330	.75	.312	Passivated	Gold (C)	1301-015-K005	***
9	2	.330	.75	.312	Gold	Gold (C)	1301-037-G005	***
9	2	.330	.75	.312	Passivated	Gold (C)	1301-037-K005	***

Right Angle Plug—For Flexible Cable

Figure 1
(Crimp type, shown with
supplied heat-shrink tubing)

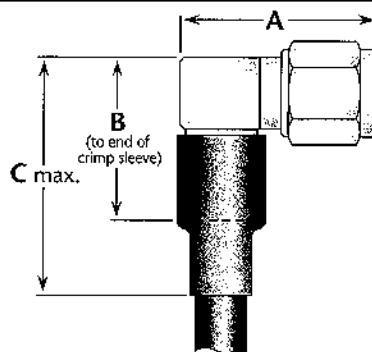

Cable Group	Figure	Dimensions			Plating		Delta P/N	Assembly Procedure/ Trim Code
		A	B	C	Body	Contact		
5	1	.68	.60	1.06	Gold	Gold (C)	1307-017-G001	L/03
5	1	.68	.60	1.06	Passivated	Gold (C)	1307-017-K001	L/03
6	1	.68	.60	1.06	Gold	Gold (C)	1307-013-G001	L/03
6	1	.68	.60	1.06	Passivated	Gold (C)	1307-013-K001	L/03
9	1	.68	.60	1.06	Gold	Gold (C)	1307-036-G001	L/03
9	1	.68	.60	1.06	Passivated	Gold (C)	1307-036-K001	L/03
10	1	.68	.60	1.06	Gold	Gold (C)	1307-100-G001	L/03
10	1	.68	.60	1.06	Passivated	Gold (C)	1307-100-K001	L/03
11	1	.68	.60	1.06	Gold	Gold (C)	1307-038-G001	L/03
11	1	.68	.60	1.06	Passivated	Gold (C)	1307-038-K001	L/03