

N/M-N/M RG-402 (FEP Jacket) FLEXIBLE CABLE,18GHz

SCA1814-0505-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @< 18GHZ TYPICAL

RAW CABLE: RG402(FEP Jacket)

TYPICAL LOSS (EXCLUDING CONNECTORS)

@0.4GHZ : 0.08dB/Ft

@1GHZ: 0.13dB/Ft

@3GHZ: 0.23dB/Ft

@5GHZ: 0.3dB/Ft

@10GHZ: 0.45dB/Ft

@18GHZ: 0.64dB/Ft


CONNECTORS:

BNC: BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

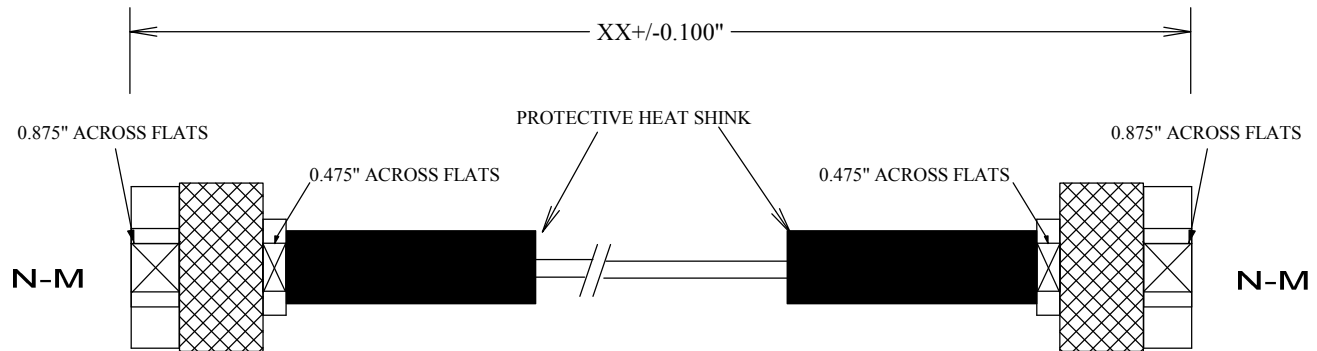

MEASUREMENTS BELOW ARE TYPICAL

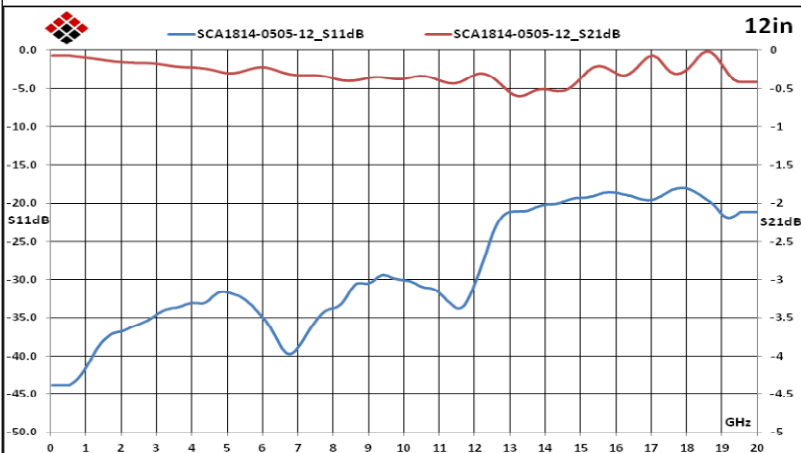

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M-N/M RG-402 (FEP Jacket)
FLEXIBLE CABLE,18GHz

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCA1814-0505-XX	--

SCALE

SHEET