




SMP/F-SMP/F FLEXIBLE CABLES 18GHZ SF086

SCA68086-XX

SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.35:1 @<18GHZ TYPICAL

RAW CABLE: HARVERHILL SF086
TYPICAL LOSS (EXCLUDING CONNECTORS)
@0.5GHz 0.15dB/ft
@1GHz 0.22dB/ft
@5GHz 0.5dB/ft
@10GHz 0.8dB/ft
@20GHz 1.3dB/ft
Center Conductor CPCW Ø0.02 inch
OUTER SHIELD DIAMETER: .087"
CONNECTORS:
SMA: Nickel PLATED BRASS
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A
SMP(GPOtm COMPATIBLE)
Au PLATED BeCu
ROHS COMPLIANT

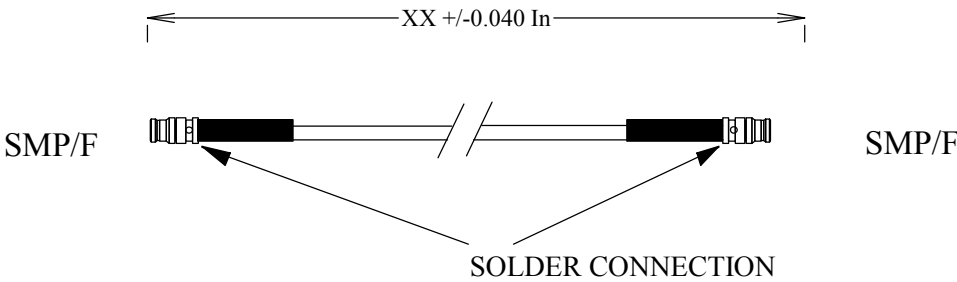

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE			
SMP/F-SMP/F FLEXIBLE CABLES 18GHZ SF086			
SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCA68086-XX	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical