



TNC/M-RA-TNC/M FLEXIBLE CABLES 3GHZ RG316

SCB111729-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 3GHZ TYPICAL

RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@1GHz: 0.26 DB/FT
@2GHz: 0.38 DB/FT
@3GHz: 0.47 DB/FT

CONNECTORS:
BNC: BRASS
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C
ROHS COMPLIANT

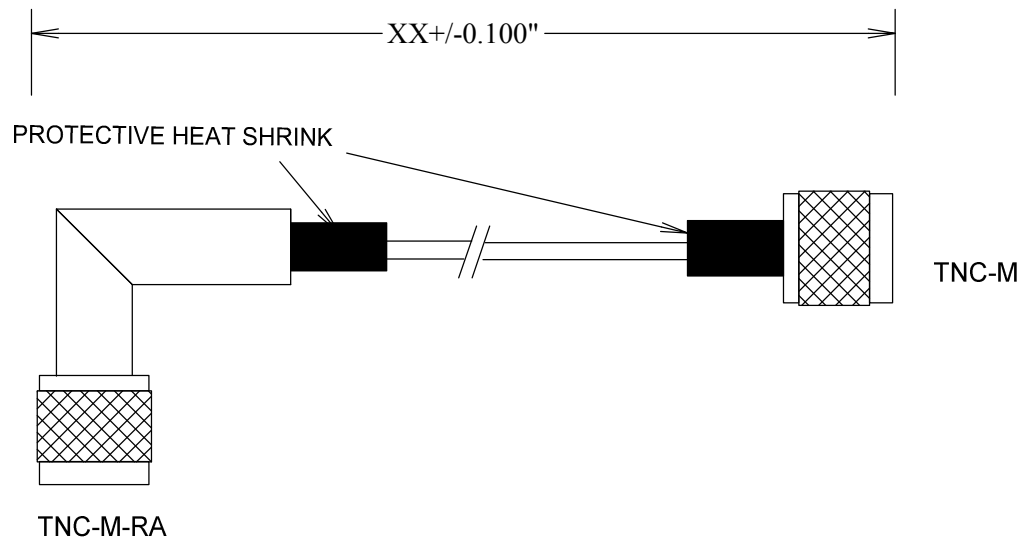

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE
TNC/M-RA-TNC/M FLEXIBLE CABLES 3GHZ RG316

ALL DIMENSIONS IN inches(MM) Typical	SIZE	CAGE CODE	DWG NO	REV
	A	3FKR5	SCB111729-XX	--
	SCALE			SHEET