

N/M - TNC/M- FLEXIBLE CABLES 6GHZ LMR400

SCB112134-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 6GHZ TYPICAL

RAW CABLE: LMR400
TYPICAL LOSS (EXCLUDING CONNECTORS)
@1GHz: 0.041 DB/FT
@2GHz: 0.06DB/FT
@4Ghz: 0.087db/ft
@6GHz: 0.11 DB/FT
@8GHz 0.13 DB/FT

CONNECTORS:
BNC: BRASS
CONTACTS Au
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C
ROHS COMPLIANT

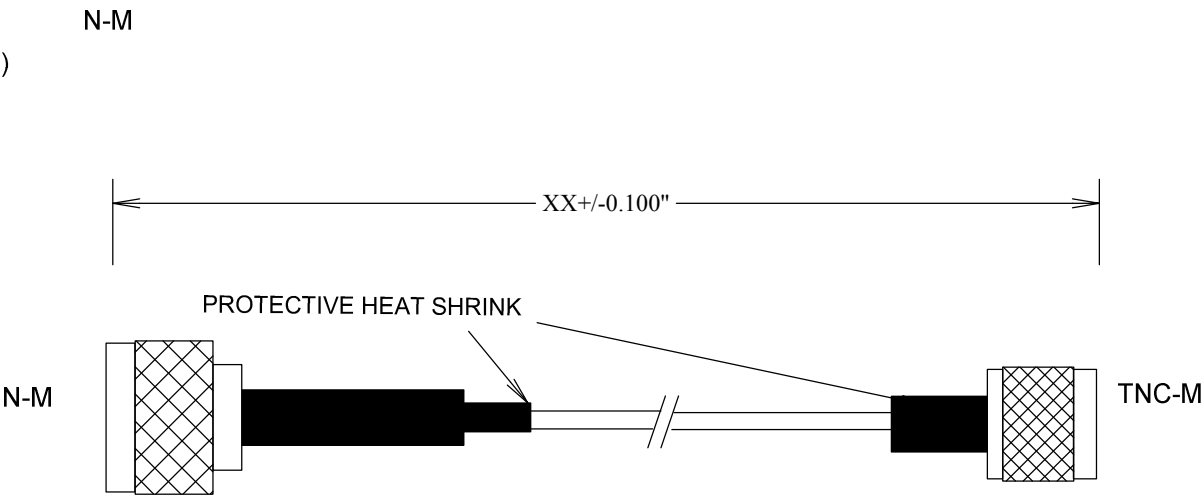

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M - TNC/M- FLEXIBLE CABLES 6GHZ LMR400

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB112134-XX

REV

--

ALL DIMENSIONS IN inches(MM) Typical

SCALE

SHEET