

SMA/MRA-SMA/MRA FLEXIBLE CABLES 6GHZ RG142


SCB15037-XX

SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 6GHZ TYPICAL

RAW CABLE: RG142
TYPICAL LOSS (EXCLUDING CONNECTORS)
@0.1GHz 0.04 dB/ft
@1GHz 0.13 dB/ft
@3GHz 0.24 dB/ft
@5GHz 0.32 dB/ft
CONNECTORS:
BRASS SMA torque 5-in-lbs
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C
ROHS COMPLIANT

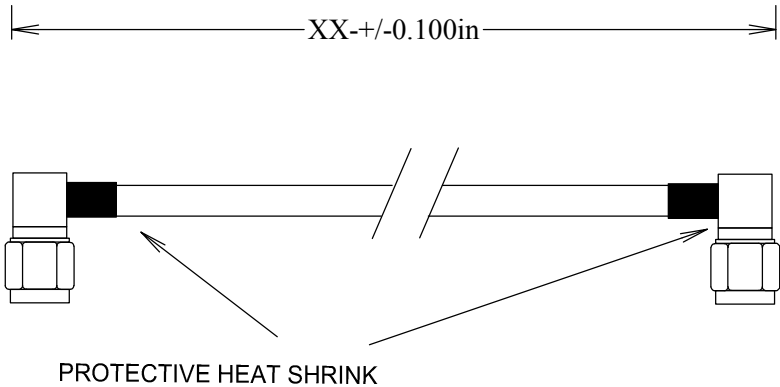

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMA/MRA-SMA/MRA FLEXIBLE CABLES 6
GHZ RG142**

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB15037-XX	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical