

# N/M-N/F BKHD FLEXIBLE CABLES 3GHZ RG316

SCB15160-XX

## SPECIFICATIONS

### CABLE ASSEMBLY:

VSWR:1.2:1 @ < 3GHZ TYPICAL

### RAW CABLE: RG316

TYPICAL LOSS (EXCLUDING CONNECTORS)

@ 100MHZ: 0.08 DB/FT

@ 1GHZ: 0.26 DB/FT

@ 2GHZ: 0.38 DB/FT


@ 3GHZ: 0.47 DB/FT

### CONNECTORS: BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

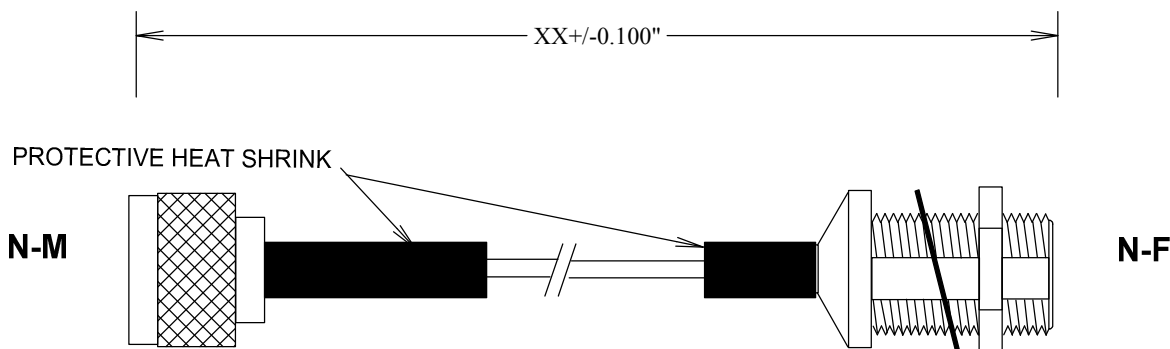

MEASUREMENTS BELOW ARE TYPICAL

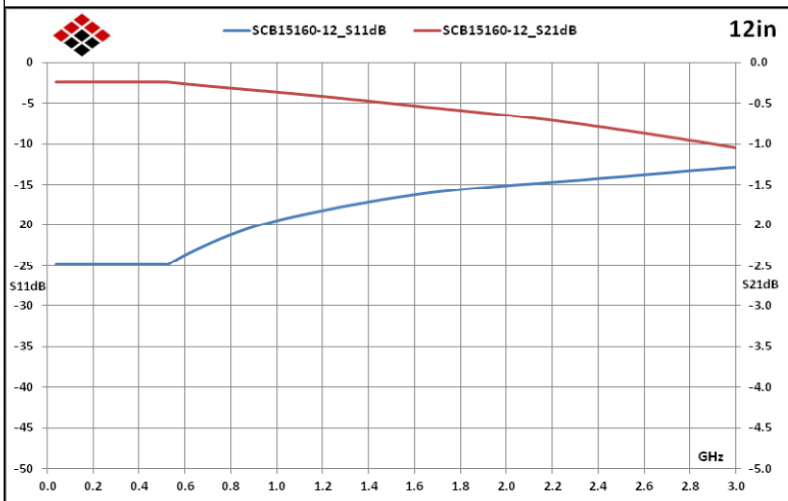

ALL DIMENSIONS IN inches(MM) Typical

<b>FAIRVIEW MICROWAVE INC.</b>			
ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
TITLE			
N/M-N/F BKHD FLEXIBLE CABLES 3GHZ RG316			
SIZE	CAGE CODE	DWG NO	REV
<b>A</b>	3FKR5	<b>SCB15160-XX</b>	--
SCALE		SHEET	