



SMB/P - SMB/P FLEXIBLE CABLES 3GHZ RG316

SCB15286-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 3GHZ TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@1GHz: 0.26 DB/FT
@2GHz: 0.38 DB/FT
@3GHz: 0.47 DB/FT

CONNECTORS:
BRASS
CONTACTS Au PLATING 30μ-in
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C
ROHS COMPLIANT

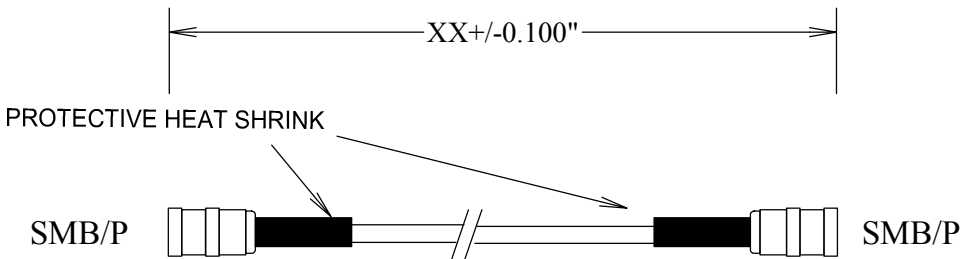

MEASUREMENTS BELOW ARE TYPICAL

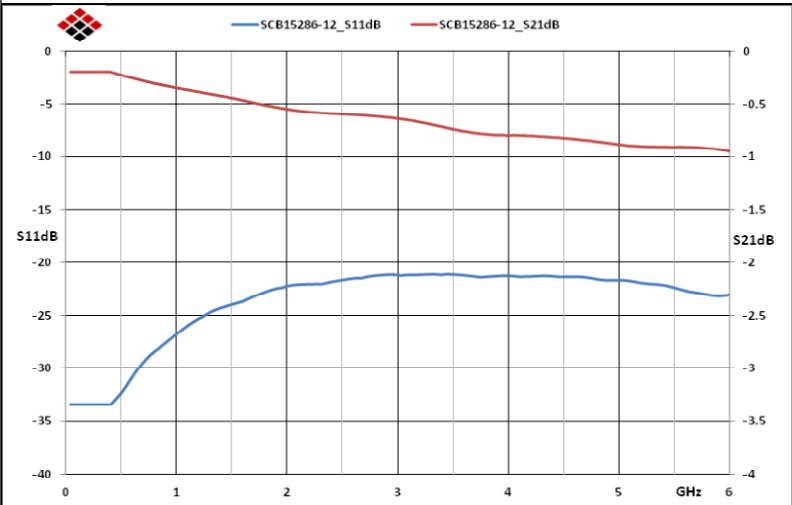

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMB/P - SMB/P FLEXIBLE CABLES 3GHZ RG316

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15286-XX

REV

--

SCALE

SHEET

ALL DIMENSIONS IN inches(MM) Typical

