

# N/M-N/M FLEXIBLE CABLES 6GHZ LMR400

SCB15580-XX

## SPECIFICATIONS

**CABLE ASSEMBLY:**

VSWR:1.2:1 @ < 6GHZ TYPICAL

**RAW CABLE: LMR400**

TYPICAL LOSS (EXCLUDING CONNECTORS)

@1GHz: 0.041 DB/FT

@2GHz: 0.06DB/FT

@4Ghz: 0.087db/ft


@6GHz: 0.11 DB/FT

**CONNECTORS: BRASS**


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

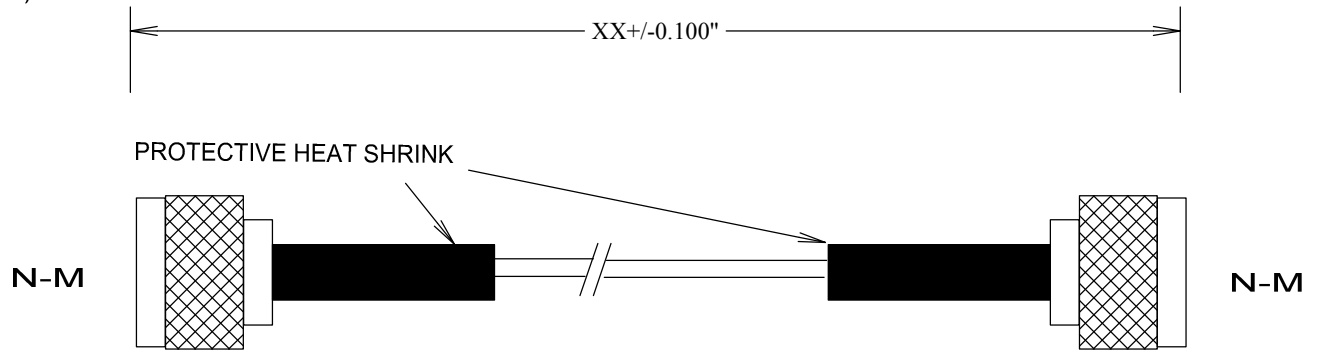

MEASUREMENTS BELOW ARE TYPICAL

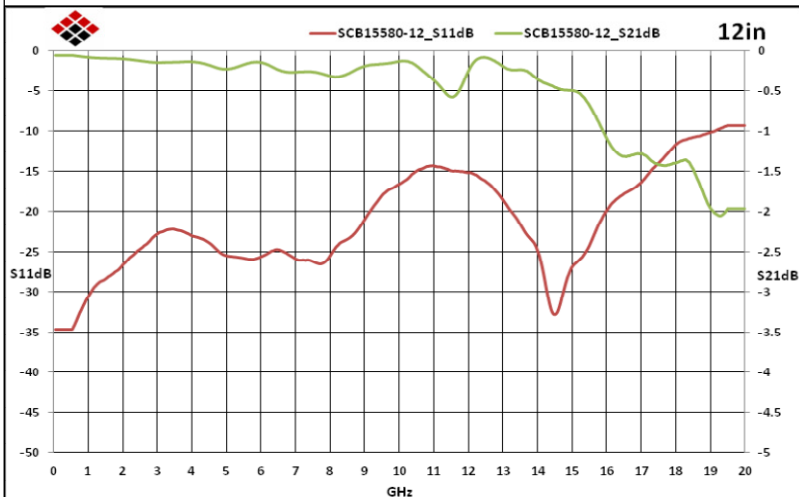

ALL DIMENSIONS IN inches(MM) Typical

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M-N/M FLEXIBLE CABLES 6GHZ LMR400

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB15580-XX	--
SCALE		SHEET	