

# N/M - TNC/M- FLEXIBLE CABLES 6GHZ LMR240

SCB15655-XX


## SPECIFICATIONS

CABLE ASSEMBLY:  
VSWR:1.2:1 @< 6GHZ TYPICAL

RAW CABLE: LMR240  
TYPICAL LOSS (EXCLUDING CONNECTORS)  
@1GHz: 0.081 DB/FT  
@2GHz: 0.116 DB/FT  
@6GHz: 0.205 DB/FT

CONNECTORS:  
BRASS  
CONTACTS Au  
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C  
ROHS COMPLIANT

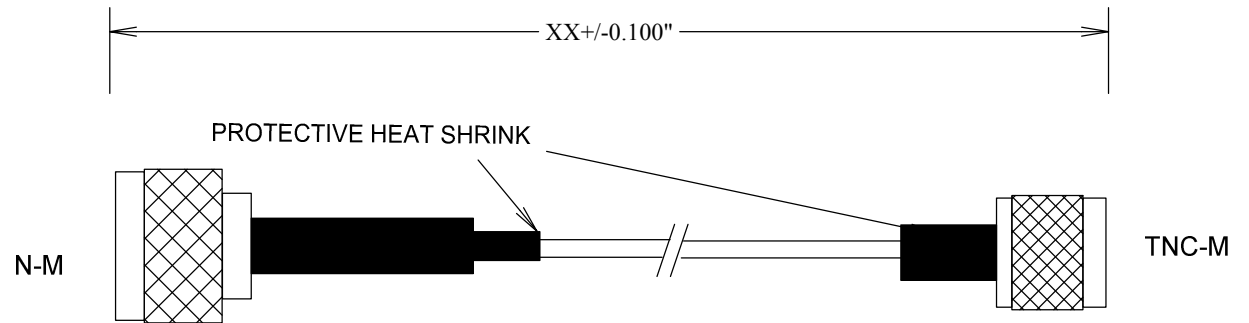

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M - TNC/M- FLEXIBLE CABLES 6GHZ LMR240

SIZE	CAGE CODE	DWG NO	REV
<b>A</b>	3FKR5	<b>SCB15655-XX</b>	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical