

TNC/F- BLKHD - MCX/M/RA BLKHD FLEXIBLE CABLES 3GHZ RG316

SCB15777-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 3GHZ TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@100MHZ: 0.08 DB/FT
@1GHz: 0.30 DB/FT
@3GHz: 0.54 DB/FT
@3GHz: 0.62 DB/FT

CONNECTORS:
BRASS
CONTACTS Au PLATING 30uin
INTERFACE: MIL-STD-348A

OP TEMP: -55 to +110°C
ROHS COMPLIANT

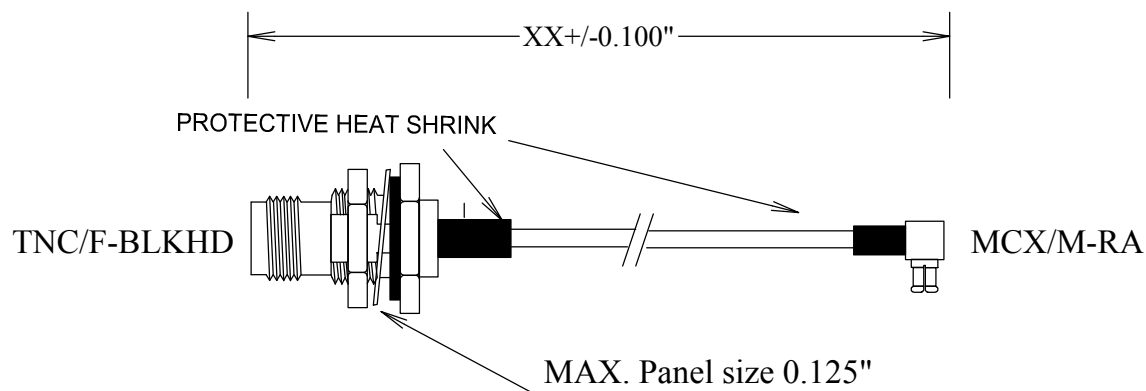

MEASUREMENTS BELOW ARE TYPICAL

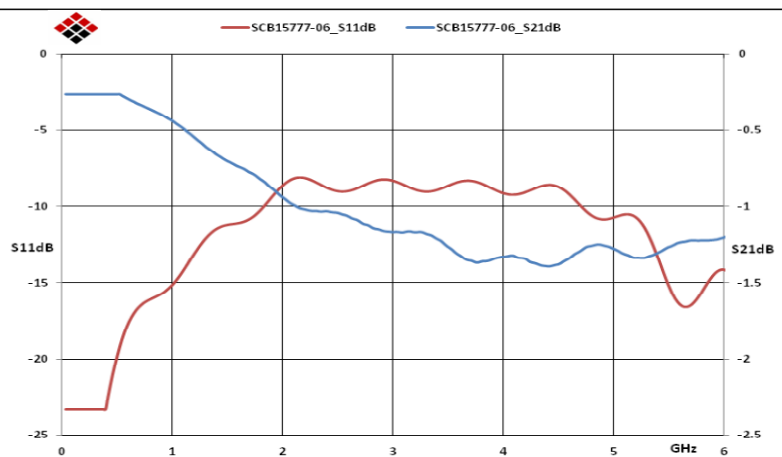

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

TNC/F- BLKHD - MCX/M/RA BLKHD FLEXIBLE CABLES
3GHZ RG316

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15777-XX

REV

--

SCALE

SHEET

ALL DIMENSIONS IN inches(MM) Typical