

TNC/M - TNC/M- FLEXIBLE CABLES 6GHZ LMR240

SCB15920-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @ < 6GHZ TYPICAL

RAW CABLE: LMR240
TYPICAL LOSS (EXCLUDING CONNECTORS)
@1GHz: 0.081 DB/FT
@2GHz: 0.116 DB/FT
@6GHz: 0.205 DB/FT
@8GHz 0.238 DB/FT

CONNECTORS:
BNC: BRASS
CONTACTS Au
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C
ROHS COMPLIANT

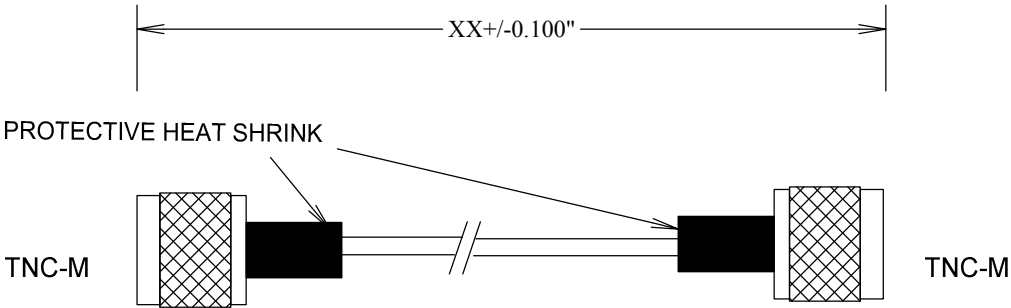

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

TNC/M - TNC/M- FLEXIBLE CABLES 6GHZ LMR240

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB15920-XX	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical