



SMB/P - MMCX/P FLEXIBLE CABLES 3GHZ RG316

SCB18892-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @3GHZ TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@1GHZ: 0.26 DB/FT
@2GHZ: 0.38 DB/FT
@3GHz: 0.47 DB/FT

CONNECTORS:
BRASS
CONTACTS Au PLATING 30μ-in
INTERFACE: MIL-STD-348A

OP TEMP: -55-200°C
ROHS COMPLIANT

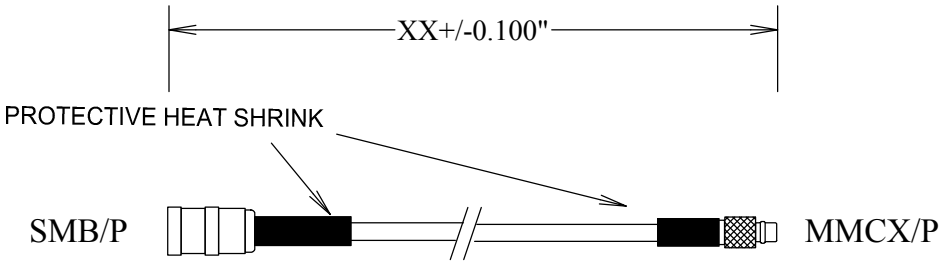

MEASUREMENTS BELOW ARE TYPICAL

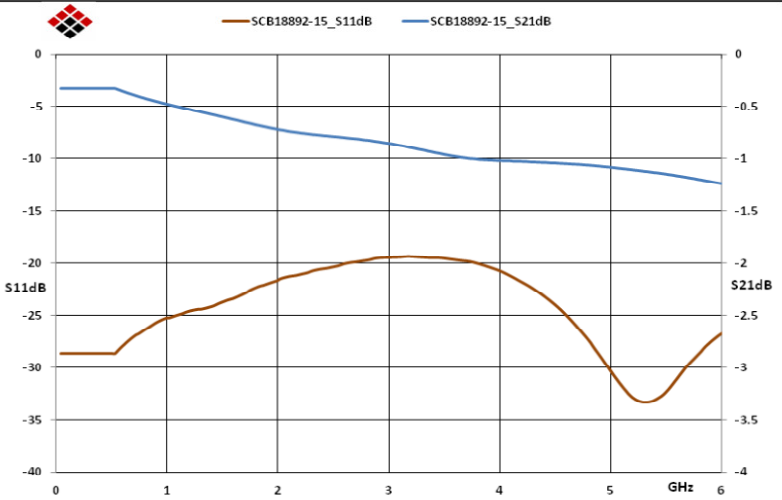

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMB/P - MMCX/P FLEXIBLE CABLES
3GHZ RG316**

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCB18892-XX	--
SCALE	SHEET		

