

MINISMP/F-MINISMP/F HF086 FLEXIBLE CABLE


SCF87086-XX

SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 2GHZ TYPICAL

RAW CABLE: HARVERHILL HF086
TYPICAL LOSS (EXCLUDING CONNECTORS)
@1GHz: 0.23 dB/ft
@3GHz: 0.39 dB/ft
@5GHz: 0.52 dB/ft
@10GHz: 0.8 dB/ft
@18GHz: 1.1 dB/ft
CENTER CONDUCTOR DIAMETER: 0.0201"
OUTER SHIELD DIAMETER: .086"
OVERALL DIAMETER: 0.104"

CONNECTORS:
Body and Contact BeCu Au Plating
INTERFACE: MIL-STD-348A
MINISMP(GGPO™ COMPATIBLE)
OP TEMP: -55-200°C
ROHS COMPLIANT

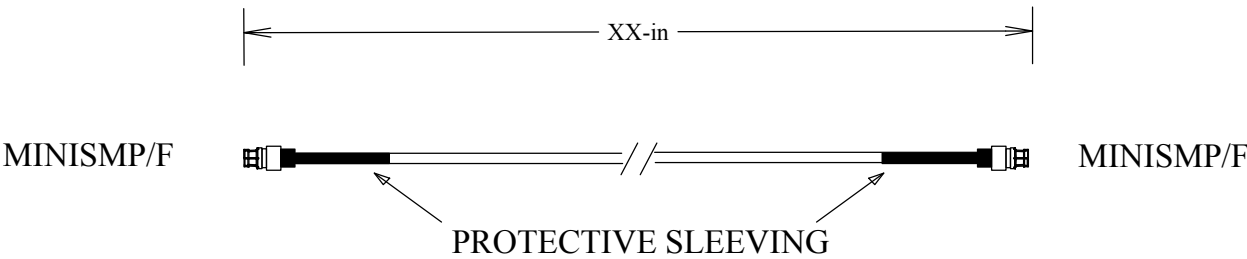

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

MINISMP/F-MINISMP/F HF086 FLEXIBLE CABLE

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SCF87086-XX	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical