

TYPE N INNER/OUTER DC BLOCK 380-2700MHZ

SD3083

SPECIFICATIONS

ELECTRICAL:


FREQUENCY: 380 MHz - 2700 GHz
VSWR: 1.4 MAX
INSERTION LOSS: 0.15 dB MAX
VOLTAGE RATING: 200 VOLTS
AVERAGE POWER: 250 WATTS
IMPEDANCE: 50 OHMS

MECHANICAL:


MATERIAL BODY: TRIMETAL
CONTACTS: GOLD PLATED

ENVIRONMENTAL:

TEMP: -55°C TO +125°C

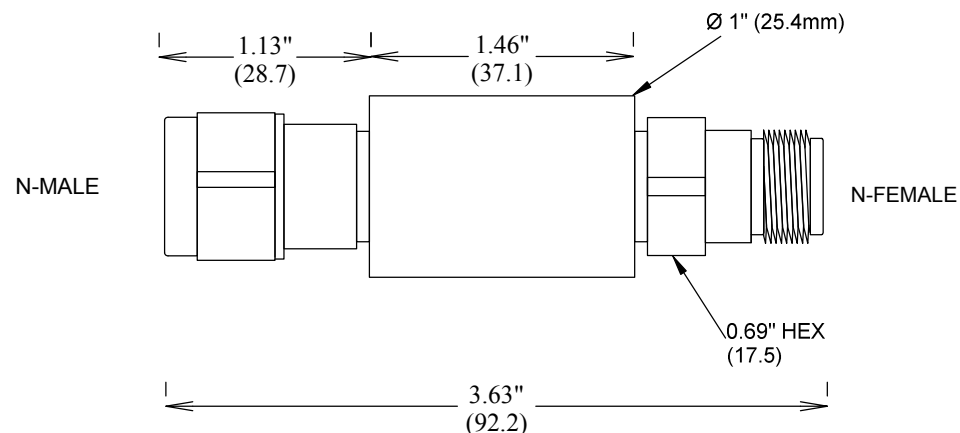

MEASUREMENTS BELOW ARE TYPICAL

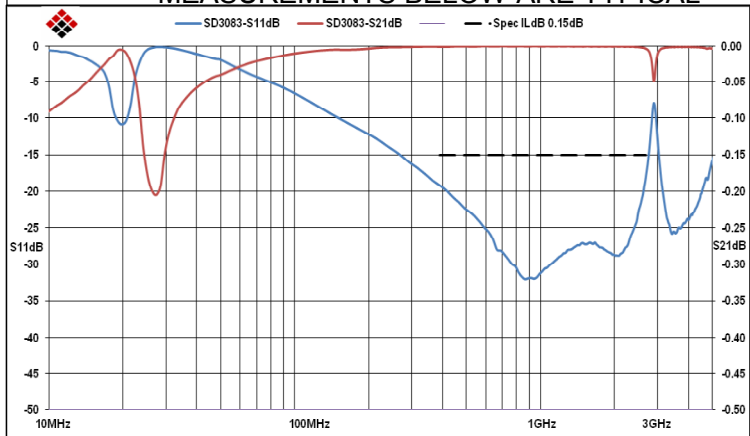

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**TYPE N INNER/OUTER DC BLOCK
380-2700MHZ**

SIZE

A

CAGE CODE

3FKR5

DWG NO

SD3083

REV

A

ALL DIMENSIONS IN inches(MM) Typical

SCALE

SHEET