

2.92 FORMABLE SEMIRIGID CABLES

SPECIFICATIONS


CABLE ASSEMBLY:
FREQUENCY: 0-40GHZ
VSWR 1.35:1 MAX @ 40GHZ

CABLE:
086B MICROCOAX UT-85-FORM (TIN DIPPED)
DIAMETER: .086"
LOSS: 1.3 DB/FT 20GHZ (EXC CONN'S)
LOSS: 1.8 DB/FT 40GHZ (EXC CONN'S)

CONNECTORS:
2.92mm MALE
BODY: PASS. STAINLESS STEEL
PIN: Au PLATED MIL-G-45204
8-10 in-lbs TORQUE


TEMPERATURE: -55°C to +100°C

RoHS COMPLIANT

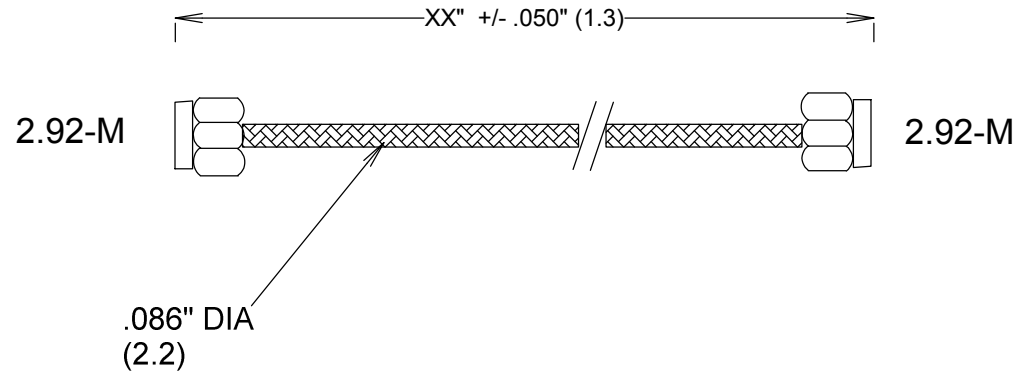

THESE CABLES CAN BE FORMED BY HAND;
THEY RETAIN THEIR SHAPE UPON FORMING

MEASUREMENTS BELOW ARE TYPICAL

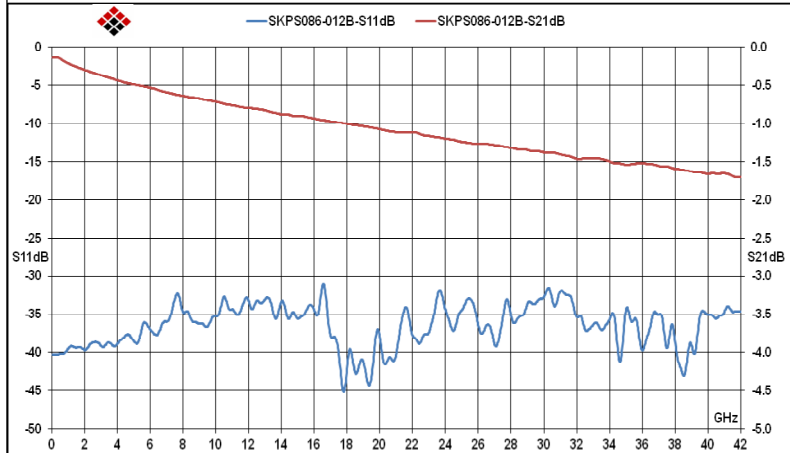

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

2.92 FORMABLE SEMIRIGID CABLES

| SIZE | CAGE CODE | DWG NO | REV |
|----------|-----------|-----------------|-----|
| A | 3FKR5 | SKPS086B | -- |
| SCALE | | SHEET | |