

1.85 FORMABLE SEMIRIGID CABLES

SKV086-XXB


SPECIFICATIONS

CABLE ASSEMBLY:
FREQUENCY: 0-65GHZ
VSWR 1.5:1 MAX @ 65GHZ

CABLE:
086B MICROCOAX UT-85-FORM (TIN DIPPED)
DIAMETER: .086"
LOSS: 1.1 DB/FT 18GHZ (EXC CONN'S)
LOSS: 2.0 DB/FT 40GHZ (EXC CONN'S)
LOSS: 2.4 DB/FT 65GHZ (EXC CONN'S)

CONNECTORS:
1.85mm MALE
BODY: PASS. STAINLESS STEEL
PIN: BeCu Au PLATED MIL-G-45204
8-10 in-lbs TORQUE

TEMPERATURE: -55°C to +100°C

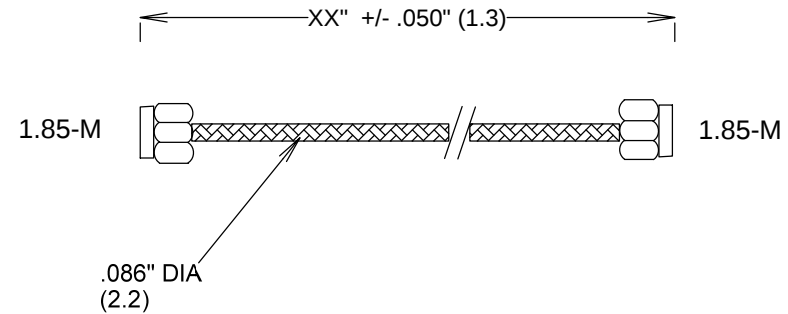

THESE CABLES CAN BE FORMED BY HAND;
THEY RETAIN THEIR SHAPE UPON FORMING

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

1.85 FORMABLE SEMIRIGID CABLES

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SKV086-XXB	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical