

N-TNC 18GHZ PRECISION ADAPTERS

SM4142, 4147, 4152, 4157

SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-18 GHZ

IMPEDANCE: 50 OHMS

VSWR: 1.15:1 MAX

MECHANICAL:

MATERIALS BODY PASS STAINLESS STEEL

FEMALE CONTACTS BeCu

CONTACTS PLATING: Au PER MIL-G-45204


DURABILITY: 500 CYCLES MIN

INSULATOR PTFE


INTERFACE MIL-STD-348A

OPERATING TEMPERATURE; -55 to 100°C


RHOS COMPLAINT

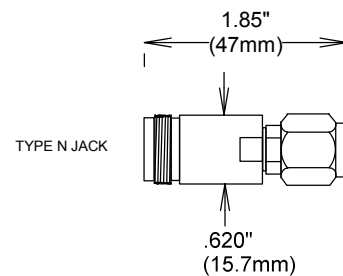


SM4142

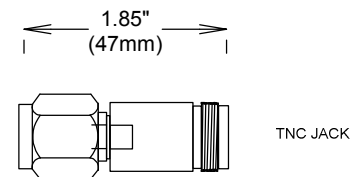

SM4157

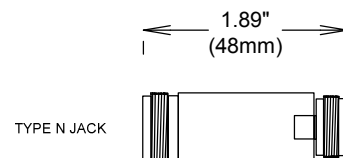


SM4147

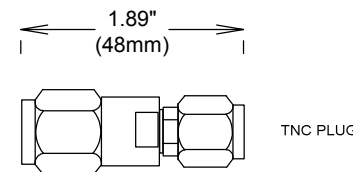

SM4152

MEASUREMENTS BELOW ARE TYPICAL

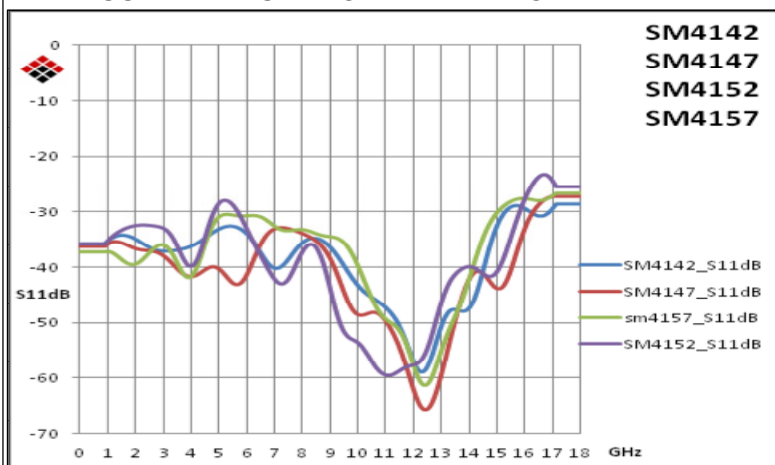

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N-TNC 18GHZ PRECISION ADAPTERS

SIZE

A

CAGE CODE

3FKR5

DWG NO

SM4142, 4147, 4152, 4157

REV

D

SCALE

SHEET