

N-SMA F/F 8GHZ FLANGE ADAPTER

SM4232A


SPECIFICATIONS

ELECTRICAL


FREQUENCY: 0-8 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.2:1 MAX
VRMS: 250 V SEA LEVEL

MECHANICAL

MATERIALS BODY NICKEL PLATED BRASS
MATERIALS CONTACTS BeCu
CONTACT PLATING: Au PER MIL-G-45204
INTERFACE: MIL-STD-348
CONTACT CAPTIVATION: 6LBS MIN AXIAL FORCE
CONTACT TORQUE: 4 IN-OUNCES MIN
DURABILITY: 100 CYCLES MIN

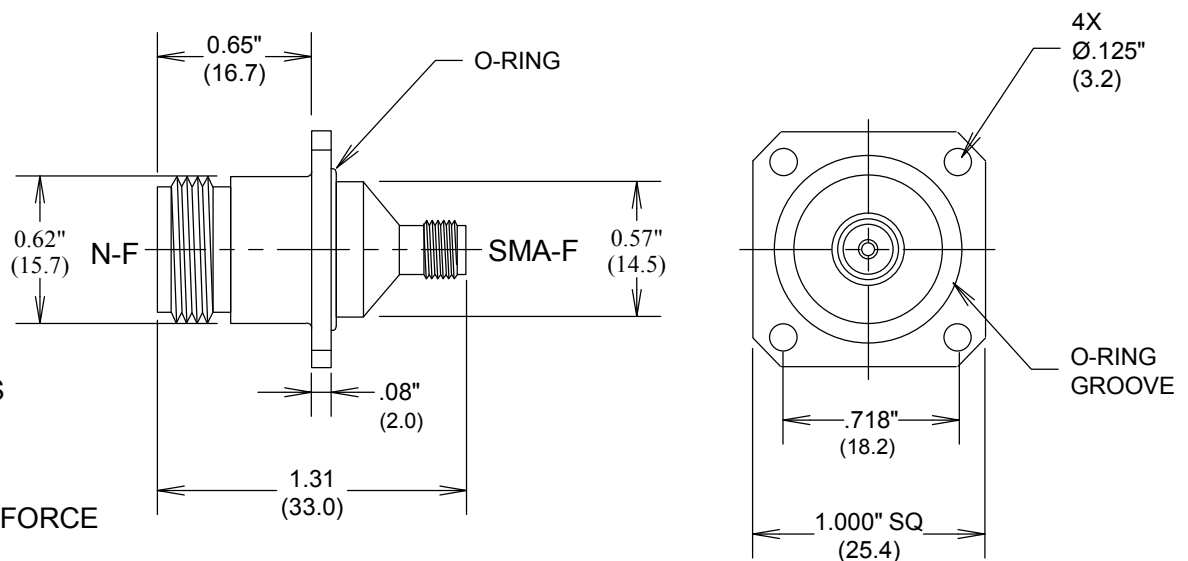

MEASUREMENTS BELOW ARE TYPICAL

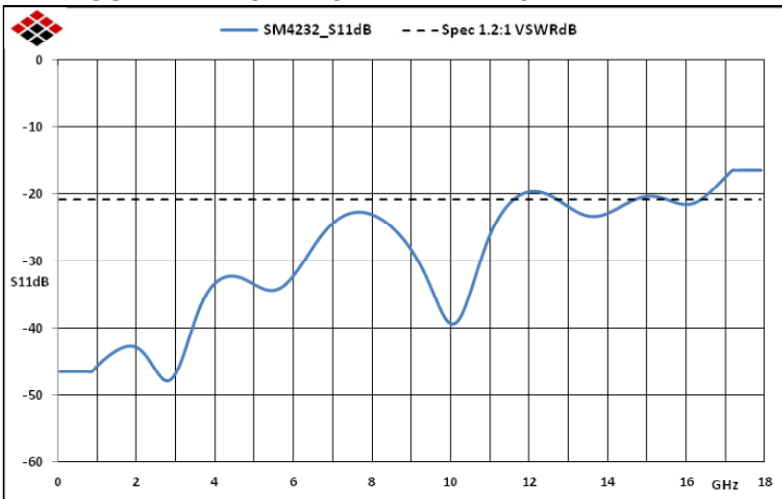

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N-SMA F/F 8GHZ FLANGE ADAPTER

SIZE

A

CAGE CODE

3FKR5

DWG NO

SM4232A

REV

--

SCALE

SHEET