

N(F)- 7/16(M) DIN ADAPTER

SM4680

SPECIFICATIONS

ELECTRICAL


FREQUENCY: 0-8 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.12:1 MAX @ 3GHZ; 1.25 @ 8GHZ
VRMS: 2700 V SEA LEVEL
DIELECTRIC WITHSTANDING VOLTAGE: 4000 V RMS
INSULATION RESISTANCE: 10000 OHMS

MECHANICAL

MATERIALS BODY NICKEL PLATED BRASS
MATERIALS CONTACTS Au PLATING MIL-G-45204
RECOMMENDED TORQUE 7-16 221 IN-LBS; N 8-14 IN-LBS
DURABILITY: 500 CYCLES MIN

ENVIRONMENTAL PER DIN 47223

ROHS COMPLIANT

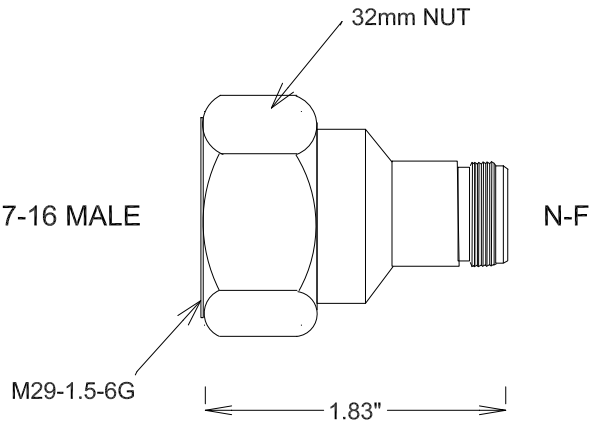

SM4680

		FAIRVIEW MICROWAVE INC.			
		ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM			
		TITLE			
		N(F)- 7/16(M) DIN ADAPTER			
SIZE		CAGE CODE	DWG NO		REV
A		3FKR5	SM4680		A
SCALE				SHEET	