

N - 7/16 ADAPTER S STEEL

SM4689

SPECIFICATIONS

ELECTRICAL

FREQUENCY: 0-6 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.15:1 MAX



MECHANICAL

MATERIALS BODY: PASS S STEEL
MALE CONTACTS: BRASS, SI PLATING
FEMALE CONTACTS: BeCu, Si PLATING
INSULATOR: TEFLON
O-RINGS: SILICONE-RUBBER
RECOMMENDED TORQUE 7-16 221 IN-LBS
DURABILITY: 500 CYCLES MIN

OPERATING TEMP: -55° TO +120° C

ROHS COMPLIANT

MEASUREMENTS BELOW ARE TYPICAL

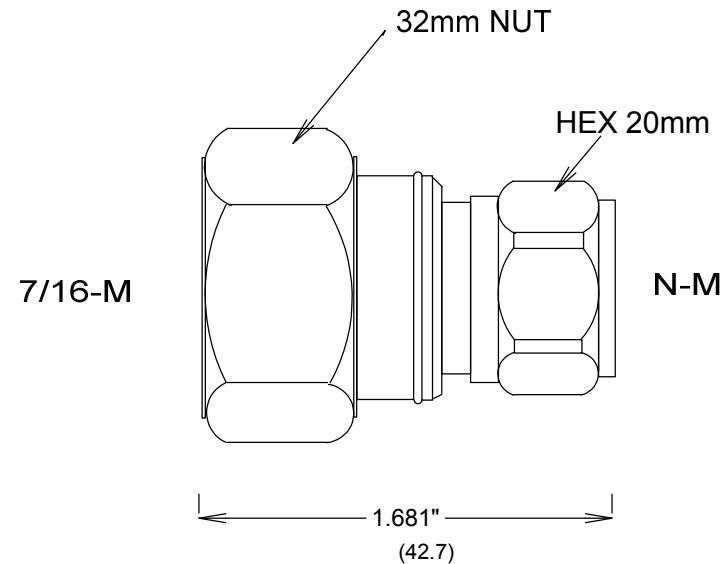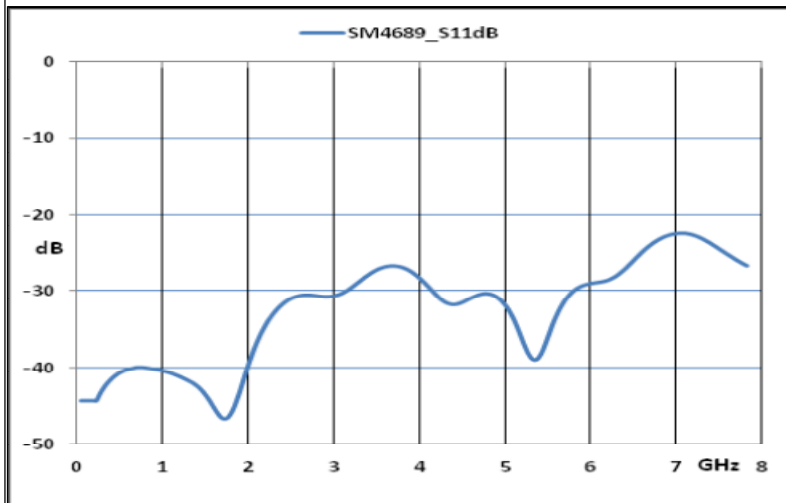

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N (M) - 7/16 (M) ADAPTER S STEEL

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM4689	--
SCALE			SHEET

ALL DIMENSIONS IN inches(MM) Typical