



SMA/M - SMA/F BLKHD FLEXIBLE CABLES RG316

FMC0212316-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 2GHZ TYPICAL

RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 0.1GHz: 0.08 DB/FT
@1GHz: 0.29 DB/FT
@3GHz: 0.54 DB/FT
@5GHz: 0.62 DB/FT

CONNECTORS:
SMA: BRASS torque 5-in-lbs
CONTACTS Au PLATING 30uin
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C
ROHS COMPLIANT

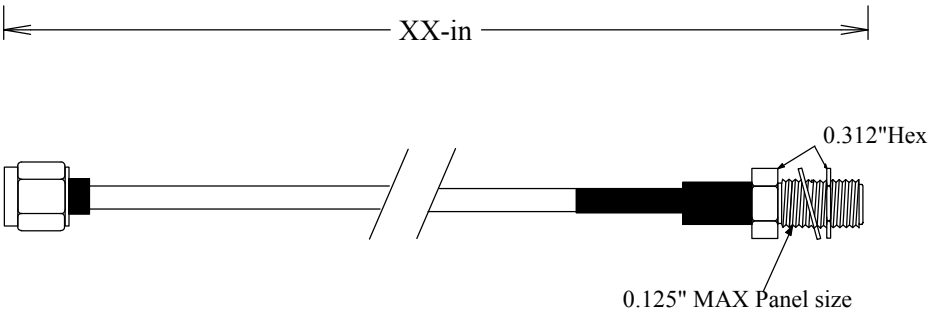

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M - SMA/F BLKHD FLEXIBLE CABLES RG316

ALL DIMENSIONS IN inches(MM) Typical	SIZE	CAGE CODE	DWG NO	REV
	A	3FKR5	FMC0212316-XX	--
	SCALE		SHEET	

