



SMA/M-RA - SMA/M-RA FLEXIBLE CABLES RG316

FMC0404316-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 2GHZ TYPICAL

RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@1GHz: 0.29 DB/FT
@3GHz: 0.54DB/FT
@5GHz: 0.62 DB/FT

CONNECTORS:
SMA: BRASS torque 5-in-lbs
CONTACTS Au PLATING 30uin
INTERFACE: MIL-STD-348A

OP TEMP: -45-110°C
ROHS COMPLIANT

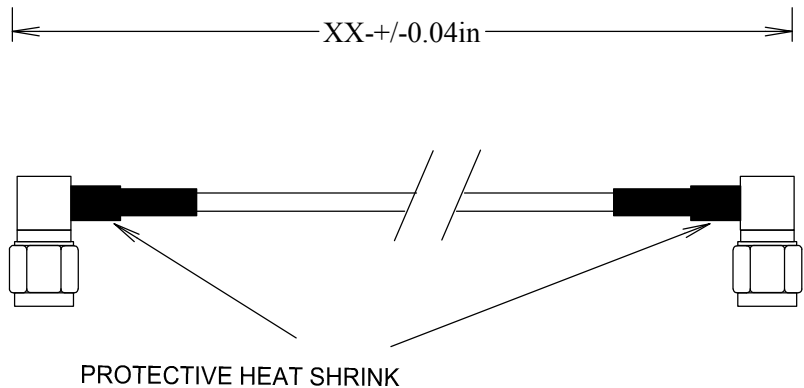

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMA/M-RA - SMA/M-RA FLEXIBLE CABLES
RG316**

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	FMC0404316-XX	--
SCALE		SHEET	

ALL DIMENSIONS IN inches(MM) Typical

