

Slide-On BMA Plug Bulkhead to Slide-On BMA Plug Bulkhead Cable FM-SR141TBJ Coax

The BMA plug slide-on bulkhead to BMA plug slide-on bulkhead cable using FM-SR141TBJ coax, part number FMCA1612, from Fairview Microwave is in-stock and ships same day. This Fairview BMA to BMA cable assembly has a plug to plug gender configuration with 50 ohm formable FM-SR141TBJ coax. Fairview Microwave's formable RF cable assemblies provide an alternative to costly pre-formed semi-rigid assemblies since they are hand formable. The FMCA1612 BMA plug to BMA plug cable assembly operates to 22 GHz. Our RF cable assembly with BMA bulkhead interface allows designers to create external connections on their product enclosures, and can be used in a variety of other rack mount and panel mount applications.

Custom versions of most RF cable assemblies can be built and shipped same day. Custom cable assembly lengths can be obtained by specifying the desired length on the web site at time of order or by contacting a sales representative. Other RF cable assembly value added services including connector orientation or clocking, heat shrink booting and labeling are also available. RF testing can also be performed to document the electrical performance of your cable assembly.

Electrical Specifications

| Description | Min | Typ | Max | Units |
|-------------------------|-----|-------------|-------|--------------|
| Frequency Range | DC | | 22 | GHz |
| VSWR | | | 1.5:1 | |
| Return Loss | | | 15.56 | dB |
| Velocity of Propagation | | 70 | | % |
| RF Shielding | 100 | | | dB |
| Group Delay | | 1.43 [4.69] | | ns/ft [ns/m] |
| Capacitance | | 29 [95.14] | | pF/ft [pF/m] |
| Operating Voltage (AC) | | | 350 | Vrms |

Performance by Frequency

| Description | F1 | F2 | F3 | F4 | F5 | Units |
|-----------------------|------|------|------|------|------|-------|
| Frequency | 1 | 2 | 4.5 | 9 | 22 | GHz |
| Insertion Loss (Max.) | 0.12 | 0.16 | 0.27 | 0.39 | 0.65 | dB/ft |
| | 0.39 | 0.52 | 0.89 | 1.28 | 2.13 | dB/m |

Electrical Specification Notes:

Insertion Loss does not include the loss of the connectors. Insertion Loss is estimated as 0.1 dB per connector.

Mechanical Specifications

Cable Assembly

Diameter 0.315 in [8 mm]

Cable

Cable Type FM-SR141TBJ
Impedance 50 Ohms
Inner Conductor Type Solid



Configuration:

- Slide-On BMA Plug Bulkhead
- Slide-On BMA Plug Bulkhead
- FM-SR141TBJ

Features:

- Max Frequency 22 GHz
- Shielding Effectivity > 100 dB
- 70% Phase Velocity
- FEP Jacket

Applications:

- General Purpose
- Laboratory Use
- Rack and Panel
- BMA Cable RF Backplanes
- Phased Array Interconnects
- High Speed Switching Networks
- Blind Mate BMA Test

Fairview Microwave
301 Leora Ln., Suite 100
Lewisville, TX 75056
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

| | |
|--------------------------------------|---------------------------|
| Inner Conductor Material and Plating | Copper Clad Steel, Silver |
| Dielectric Type | PTFE |
| Number of Shields | 1 |
| Shield Layer 1 | Tinned Copper Braid |
| Jacket Material | FEP, Black |
| Jacket Diameter | 0.161 in [4.09 mm] |
| One Time Minimum Bend Radius | 0.315 in [8 mm] |
| Repeated Minimum Bend Radius | 1.575 in [40.01 mm] |

Connectors

| Description | Connector 1 | Connector 2 |
|-------------------------------|--------------------|--------------------|
| Type | BMA Plug | BMA Plug |
| Mount Method | Bulkhead | Bulkhead |
| Impedance | 50 Ohms | 50 Ohms |
| Connection Method | Slide-On | Slide-On |
| Contact Material & Plating | Bronze, Gold | Bronze, Gold |
| Contact Plating Spec. | 51.18μ in. minimum | 51.18μ in. minimum |
| Dielectric Type | PTFE | PTFE |
| Outer Cond Material & Plating | Brass, Tri-Metal | Brass, Tri-Metal |
| Outer Cond Plating Spec. | 78.74μ in. minimum | 78.74μ in. minimum |
| Body Material & Plating | Brass, Tri-Metal | Brass, Tri-Metal |
| Body Plating Spec. | 78.74μ in. minimum | 78.74μ in. minimum |
| Hex Size | 8 mm | 8 mm |

Mechanical Specification Notes:

*All cable assemblies have a length tolerance of 1.5% or $\pm 3/8"$, whichever is greater.

Environmental Specifications

Temperature


Operating Range -55 to +125 deg C

Compliance Certifications (see [product page](#) for current document)

Plotted and Other Data

Notes:

Typical Performance Data

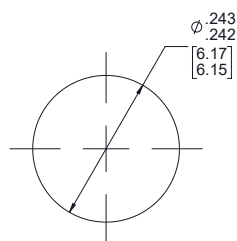

MOUNTING HOLE



How to Order

Part Number Configuration:

FMCA1612 - xx uu

cm = Centimeters
 <blank> = Inches
 Length

Example: FMCA1612-12 = 12 inches long cable
 FMCA1612-100cm = 100 cm long cable


Slide-On BMA Plug Bulkhead to Slide-On BMA Plug Bulkhead Cable FM-SR141TBJ Coax from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [Slide-On BMA Plug Bulkhead to Slide-On BMA Plug Bulkhead Cable FM-SR141TBJ Coax FMCA1612](#)

URL: <https://www.fairviewmicrowave.com/bma-plug-bma-plug-cable-fm-sr141tbj-coax-fmca1612-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.



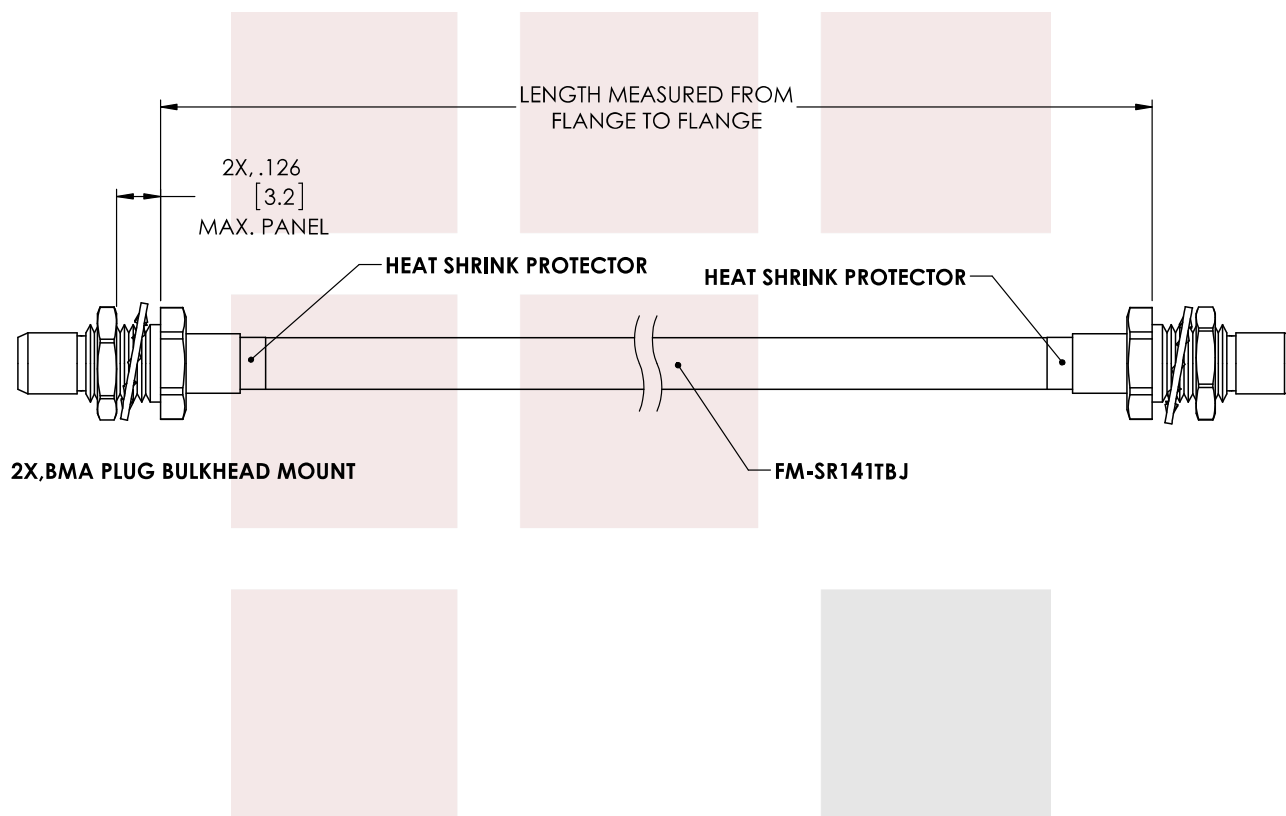

STANDARD TOLERANCES

.X ±0.2
.XX ±0.01
.XXX ±0.005

*STANDARD TOLERANCES APPLY
ONLY TO DIMENSIONS IN INCHES

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

NOTES:
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN INCHES [mm].

| | | | | |
|--|--------------------|-------|--------------------|--------|
| TITLE Slide-On BMA Plug Bulkhead to Slide-On BMA Plug Bulkhead Cable FM-SR141TBJ Coax | DWG NO FMCA1612 | | CAGE CODE 3FKR5 | |
| | CAD FILE 12/20/17 | SHEET | SCALE N/A SIZE A | CN2245 |