

Coax Cable Stripper for RG59, RG62, RG6, RG7, RG11, RG213, RG8

Configuration

Tool Type	Coax Cable Stripper
Cable Type	RG59, RG62, RG6, RG7, RG11, RG213, RG8

Mechanical Specifications

Size

Length	7.28 in [184.91 mm]
Width	4.76 in [121 mm]
Height	1.1 in [27.94 mm]
Weight	0.056 lbs [25.4 g]

Compliance Certifications (see [product page](#) for current document)

Notes:

- Values at 25 °C, sea level

Coax Cable Stripper for RG59, RG62, RG6, RG7, RG11, RG213, RG8 from Fairview Microwave is in-stock and available to ship same-day. All of our RF/microwave products are available off-the-shelf from our ISO 9001:2008 certified facilities in Lewisville, Texas. Fairview Microwave is RF on-demand.

For additional information on this product, please click the following link: [Coax Cable Stripper for RG59, RG62, RG6, RG7, RG11, RG213, RG8 FMTL5209](#)

URL: <https://www.fairviewmicrowave.com/coax-cable-stripper-rg59-rg62-rg6-rg7-rg11-rg213-rg8-fmtl5209-p.aspx>


The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.



Features:

- Double-ended Stripper for 1/4" (6mm) length
- Strips coaxial cables RG59, RG62, RG6, RG7, RG11, RG213, RG8
- Compact size fits in your pocket and easy storage

Fairview Microwave
301 Leora Ln., Suite 100
Lewisville, TX 75056
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

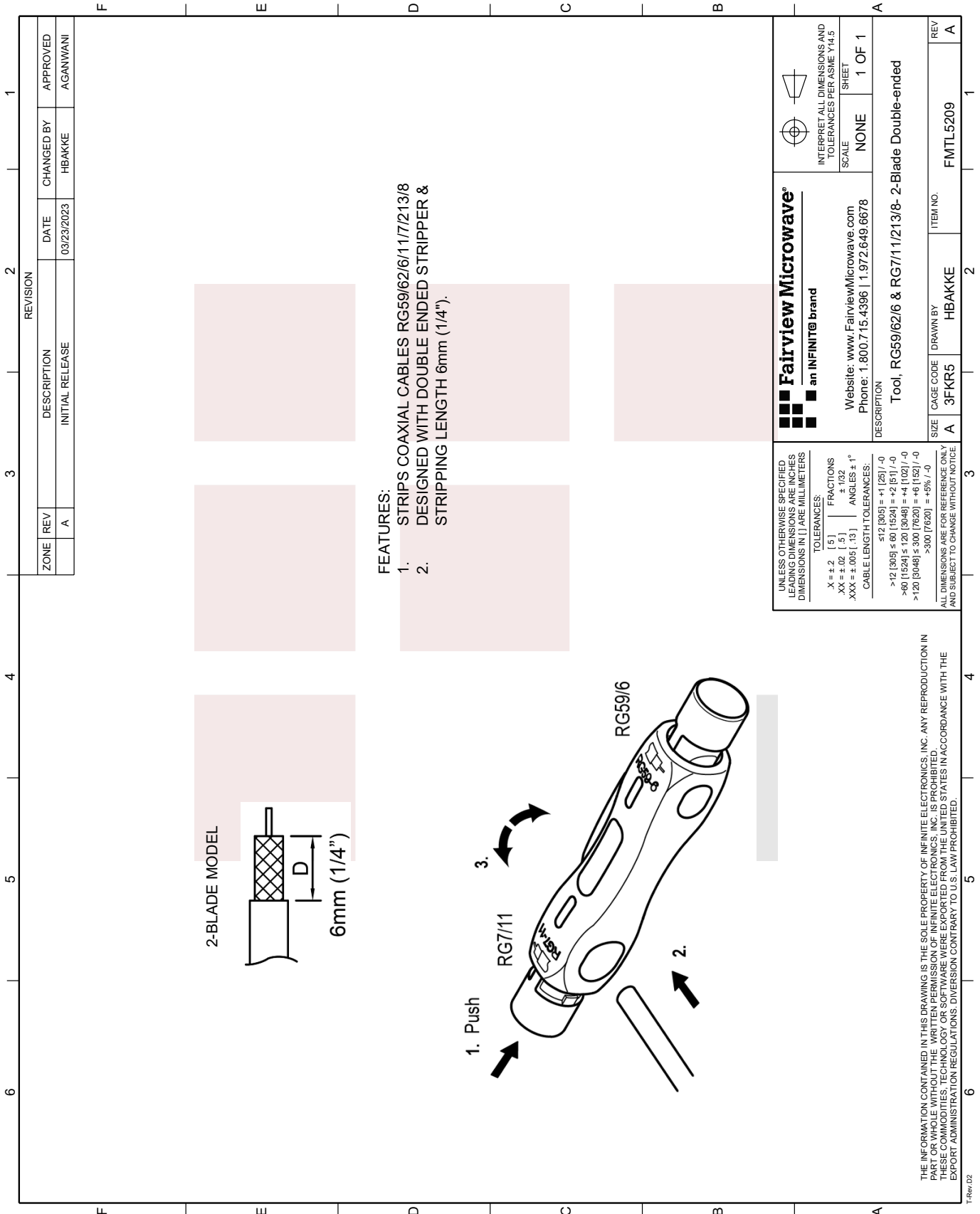

- FEATURES:**
1. STRIPS COAXIAL CABLES RG59/62/6/11/7/213/8
 2. DESIGNED WITH DOUBLE ENDED STRIPPER & STRIPPING LENGTH 6mm (1/4").

ZONE REV		DESCRIPTION		DATE		CHANGED BY		APPROVED	
	A	INITIAL RELEASE		03/23/2023		HBAKKE		AGANWANI	

REVISION		DESCRIPTION		DATE		CHANGED BY		APPROVED	
	A	INITIAL RELEASE		03/23/2023		HBAKKE		AGANWANI	

<p>Fairview Microwave an INFINIT[®] brand</p> <p>Website: www.FairviewMicrowave.com Phone: 1.800.715.4396 1.972.649.6678</p>	<p>INTERPRET ALL DIMENSIONS AND TOLERANCES PER ASME Y14.5</p>
	<p>SCALE: NONE</p> <p>SHEET: 1 OF 1</p>
<p>DESCRIPTION: Tool, RG59/62/6 & RG7/11/213/8- 2-Blade Double-ended</p>	
<p>SIZE: A</p> <p>CAGE CODE: 3FKR5</p> <p>DRAWN BY: HBAKKE</p>	<p>ITEM NO.:</p> <p>FMTL5209</p>

UNLESS OTHERWISE SPECIFIED, LEADING DIMENSIONS ARE INCHES DIMENSIONS IN [] ARE MILLIMETERS

TOLERANCES:

.X = ± .2	[.5]	FRACTIONS
.XX = ± .02	[.5]	± 1/32
.XXX = ± .005	[.13]	ANGLES ± 1°

CABLE LENGTH TOLERANCES:

≤ 12 [305]	± .125 [-0]
> 12 [305] ≤ 60 [1524]	± .25 [-0]
> 60 [1524] ≤ 120 [3048]	± .5 [-0]
> 120 [3048] ≤ 300 [7620]	± 1.0 [-0]
> 300 [7620]	± 2.0 [-0]

ALL DIMENSIONS ARE FOR REFERENCE ONLY AND SUBJECT TO CHANGE WITHOUT NOTICE

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF INFINITE ELECTRONICS, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF INFINITE ELECTRONICS, INC. IS PROHIBITED. THESE COMMODITIES, TECHNOLOGY OR SOFTWARE WERE EXPORTED FROM THE UNITED STATES IN ACCORDANCE WITH THE EXPORT ADMINISTRATION REGULATIONS. DIVERSION CONTRARY TO U.S. LAW PROHIBITED.