

Coax Cable Stripper, 1/4 inch length for RG59, RG6 with outer jacket thickness 0.65mm

Configuration

Tool Type	Coax Cable Stripper
Cable Type	RG59, RG6

Mechanical Specifications

Size	
Length	8.5 in [215.9 mm]
Width	3.78 in [96 mm]
Height	1.14 in [28.96 mm]
Weight	0.058 lbs [26.31 g]

Compliance Certifications (see [product page](#) for current document)

Notes:

- Values at 25 °C, sea level

Coax Cable Stripper, 1/4 inch length for RG59, RG6 with outer jacket thickness 0.65mm from Fairview Microwave is in-stock and available to ship same-day. All of our RF/microwave products are available off-the-shelf from our ISO 9001:2008 certified facilities in Lewisville, Texas. Fairview Microwave is RF on-demand.

For additional information on this product, please click the following link: [Coax Cable Stripper, 1/4 inch length for RG59, RG6 with outer jacket thickness 0.65mm FMTL5213](#)

URL: <https://www.fairviewmicrowave.com/coax-cable-stripper-rg59-rg6-fm-tl5213-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.




Features:

- Compatible with RG59 and RG6 coax (Outer Jacket thickness 0.65mm)
- Stripping length of 1/4" (6mm)
- Strips cable without nicking the braid or scoring the center conductor
- Designed for tight spaces such as around wall box

Fairview Microwave
301 Leora Ln., Suite 100
Lewisville, TX 75056
Tel: 1-800-715-4396 / (972) 649-6678
Fax: (972) 649-6689
www.fairviewmicrowave.com
sales@fairviewmicrowave.com

ZONE	REV	DESCRIPTION	DATE	CHANGED BY	APPROVED
	A	INITIAL RELEASE	03/23/2023	HBAKKE	AGANWANI

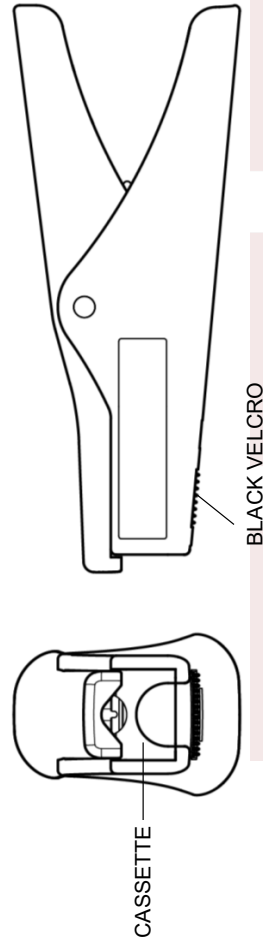


CASSETTE

 
BLACK VELCRO

FEATURES:

- STRIPS COAXIAL CABLE RG59, RG6 OF THE STUB END IN MDU BOX, WALL OUTLET OR OTHER TIGHT SPACES.
- SPINS AROUND AS A SCREWDRIVER MOTION FOR STRIPPING.
- USES BLACK VELCRO FOR FOLDING BACK THE BRAIDED SHIELD OF CABLE.
- DESIGNED WITH INTERCHANGEABLE CASSETTE & STRIPPING LENGTH (1/4").

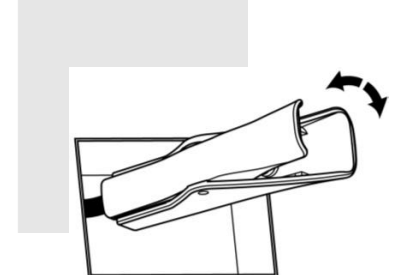

WORKS IN
TIGHT SPOTS.

CABLE TYPE	STRIPPING LENGTH (D):
RG59/6 COAXIAL CABLE (OUTER JACKET THICKNESS 0.65mm)	2 BLADES MODE  D = 6mm (1/4") D1 = 8mm (5/16")

UNLESS OTHERWISE SPECIFIED LEADING DIMENSIONS ARE INCHES DIMENSIONS IN [] ARE MILLIMETERS

TOLERANCES:

.X = ±.2 [.5]	FRACTIONS ± 1/32
.XX = ±.02 [.5]	ANGLES ± 1°
.XXX = ±.005 [.13]	

CABLE LENGTH TOLERANCES:

≤ 12 [305]	± .125 [-0]
> 12 [305] ≤ 60 [1524]	± .25 [-0]
> 60 [1524] ≤ 120 [3048]	± .5 [-0]
> 120 [3048] ≤ 300 [7620]	± 1.0 [-0]
> 300 [7620]	± 2.0 [-0]

ALL DIMENSIONS ARE FOR REFERENCE ONLY AND SUBJECT TO CHANGE WITHOUT NOTICE

Fairview Microwave[®]
an INFINIT[®] brand

Website: www.FairviewMicrowave.com
Phone: 1.800.715.4396 | 1.972.649.6678

DESCRIPTION
Tool, RG59/6 (Thickness 0.65mm) Front-Loaded Rolling Motion

INTERPRET ALL DIMENSIONS AND TOLERANCES PER ASME Y14.5 SHEET
SCALE NONE
1 OF 1

SIZE A
CAGE CODE 3FKR5
DRAWN BY HBAKKE
ITEM NO. FMTL5213

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF INFINITE ELECTRONICS, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF INFINITE ELECTRONICS, INC. IS PROHIBITED. THESE COMMODITIES, TECHNOLOGY OR SOFTWARE WERE EXPORTED FROM THE UNITED STATES IN ACCORDANCE WITH THE EXPORT ADMINISTRATION REGULATIONS. DIVERSION CONTRARY TO U.S. LAW PROHIBITED.

T-Rev D2