

POWER DIVIDER N 700-2700MHZ 4-WAY

MP0727N-4


SPECIFICATIONS

ELECTRICAL


FREQUENCY: 700-2700 MHZ
PIM <150dBc (2 tones @ +43dBm)
ISOLATION: 0 DB
POWER: 500W AVG, 3KW PEAK
IMPEDANCE: 50 OHMS
VSWR: 1.15:1 MAX , ALL PORTS
AMPLITUDE BALANCE: 0.15DB
LOSS: 6.05 DB (6.0+0.05)

MECHANICAL

MATERIALS BODY: PASSIVATED ALUMINUM
CONNECTORS: N-FEMALE, SILVER PLATING
TEMP RANGE: -35 TO +75 DEG C
MOUNTING BRACKET INCLUDED
WEIGHT: 1.2 LBS
ROHS COMPLIANT

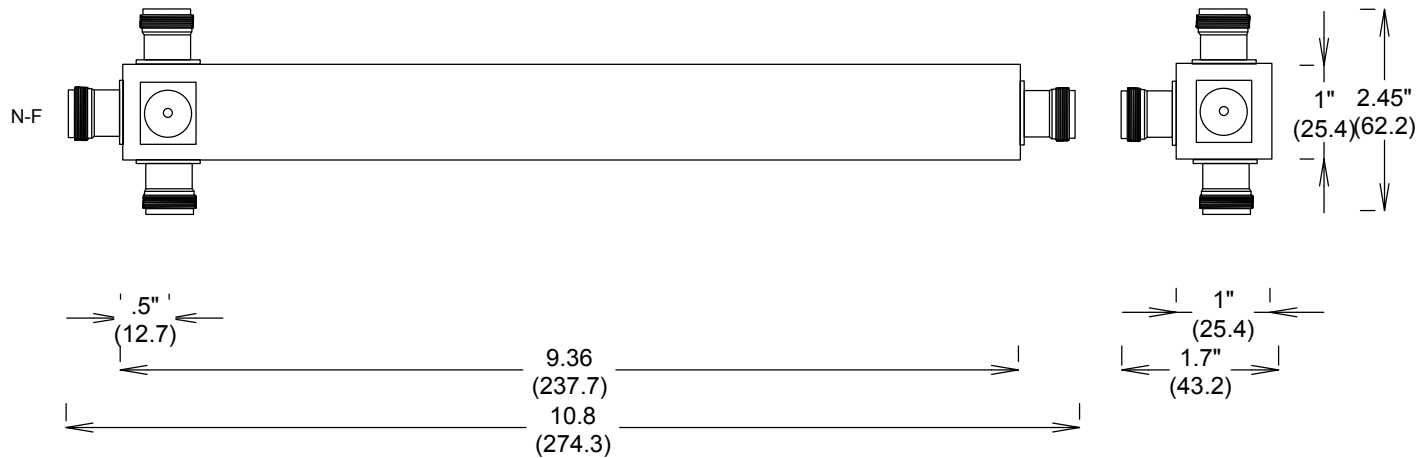

MEASUREMENTS BELOW ARE TYPICAL

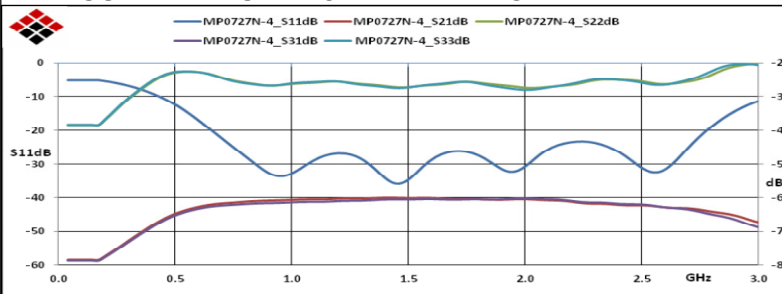

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

POWER DIVIDER N 700-2700MHZ 4-WAY

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	MP0727N-4	A
SCALE	SHEET		

ALL DIMENSIONS IN inches(MM) Typical