

7/16 FEMALE PANEL PRESSMOUNT

SC4913

SPECIFICATIONS


ELECTRICAL

FREQUENCY: 0-7.5 GHZ
IMPEDANCE: 50 OHMS
VSWR: 1.15:1 MAX

MECHANICAL

MATERIALS 7/16 BODY: TRIMETAL PLATED BRASS
FEMALE CONTACTS: SPRING BRASS INSULATOR: TEFLON
CONTACT PLATING: Si QQ-S-365
INSULATOR: TEFLON
DURABILITY: 500 CYCLES MIN
INTERFACE: DIN 47223

OPERATING TEMP: -45 TO +125 DEG C
ROHS COMPLIANT

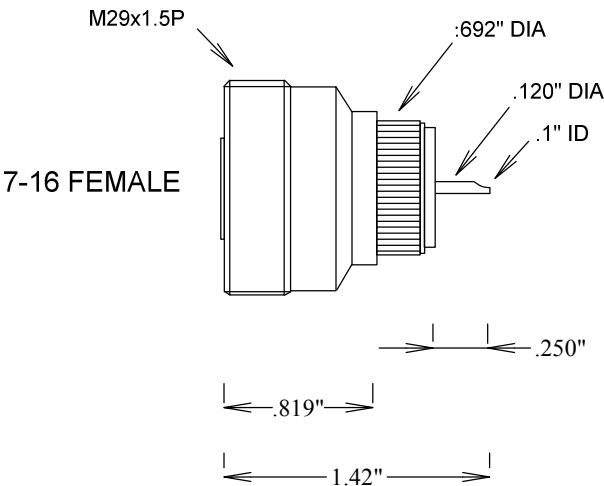

MOUNTING HOLE: .688 +/- .001"

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

7/16 FEMALE PANEL PRESSMOUNT

SIZE

A

CAGE CODE

3FKR5

DWG NO

SC4913

REV

--

SCALE

SHEET