

SMP MALE LIMITED DETENTE SHROUD .328 SPACING

SC5314

SPECIFICATIONS

ELECTRICAL:

FREQUENCY: 0-40 GHZ
IMPEDANCE: 50 OHMS
OP. TEMP RANGE: -55° to +125°C

MECHANICAL:


MATERIAL: PASSIVATED S STEEL
INTERFACE: SMP DESC 94007
LIMITED DETENTE
FORCE TO ENGAGE: 10.0 LBS MAX
FORCE TO DISENGAGE: 2.0 LBS MIN
ROHS COMPLIANT

.187"

.120" OAL

.045"


.004"

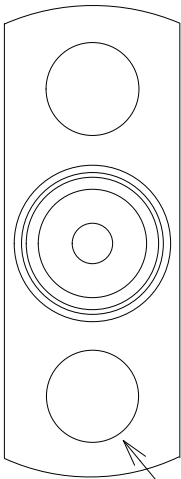

.328"

Ø.480"

 Ø.165"



Ø.155"

Ø.098" 2X

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMP MALE LIMITED DETENTE
SHROUD .328 SPACING**

SIZE

A

CAGE CODE

3FKR5

DWG NO

SC5314

REV

--

SCALE

SHEET