

## SSMC Male to SMA Male Cable RG405 Type .086 Coax and RoHS

### Electrical Specifications

Description	Min	Typ	Max	Units
Frequency Range	DC		12.4	GHz
VSWR			1.4:1	

### Mechanical Specifications

#### Cable Assembly

##### Cable

Cable Type  
Impedance

FM-SR405FL  
50 Ohms

#### Connectors


Description	Connector 1	Connector 2
Type	SSMC Male	SMA Male
Polarity	Standard	Standard
Impedance	50 Ohms	50 Ohms
Contact Material & Plating	Beryllium Copper, Gold	Brass, Gold
Contact Plating Spec.	MIL-G-45204	
Coupling Nut Material & Plating	Brass, Gold	Passivated Stainless Steel
Body Material & Plating	Beryllium Copper, Gold	Passivated Stainless Steel

### Compliance Certifications (see [product page](#) for current document)

### Plotted and Other Data

Notes:

#### Typical Performance Data

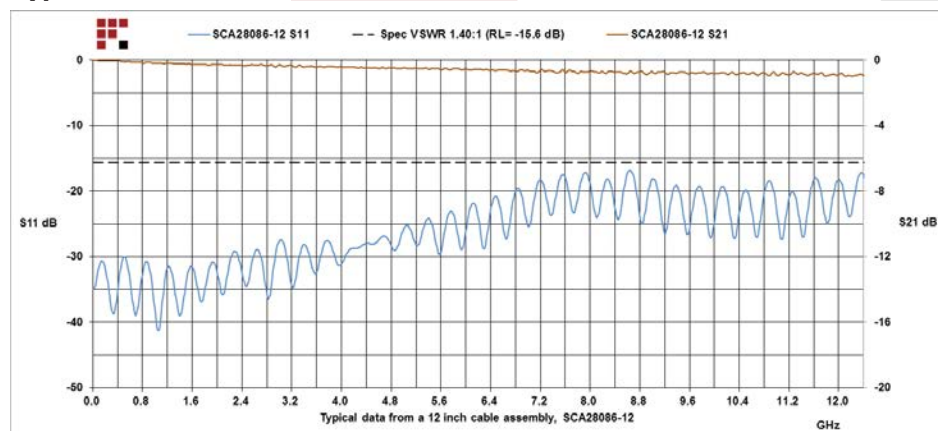

### Configuration:

- SSMC Male
- SMA Male
- FM-SR405FL

Fairview Microwave  
1130 Junction Dr. #100  
Allen, TX 75013  
Tel: 1-800-715-4396 / (972) 649-6678  
Fax: (972) 649-6689  
[www.fairviewmicrowave.com](http://www.fairviewmicrowave.com)  
[sales@fairviewmicrowave.com](mailto:sales@fairviewmicrowave.com)

## How to Order

Part Number Configuration:

**SCA28086 - xx uu**

\_\_\_\_\_ cm = Centimeters  
 \_\_\_\_\_ <blank> = Inches  
 \_\_\_\_\_ Length


Example: SCA28086-12 = 12 inches long cable  
 SCA28086-100cm = 100 cm long cable

SSMC Male to SMA Male Cable RG405 Type .086 Coax and RoHS from Fairview Microwave has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link to obtain additional part information: [SSMC Male to SMA Male Cable RG405 Type .086 Coax and RoHS SCA28086](#)

URL: <https://www.fairviewmicrowave.com/ssmc-male-sma-male-cable-sf-085-coax-sca28086-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Fairview Microwave reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Fairview Microwave does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Fairview Microwave does not assume any liability arising out of the use of any part or documentation.

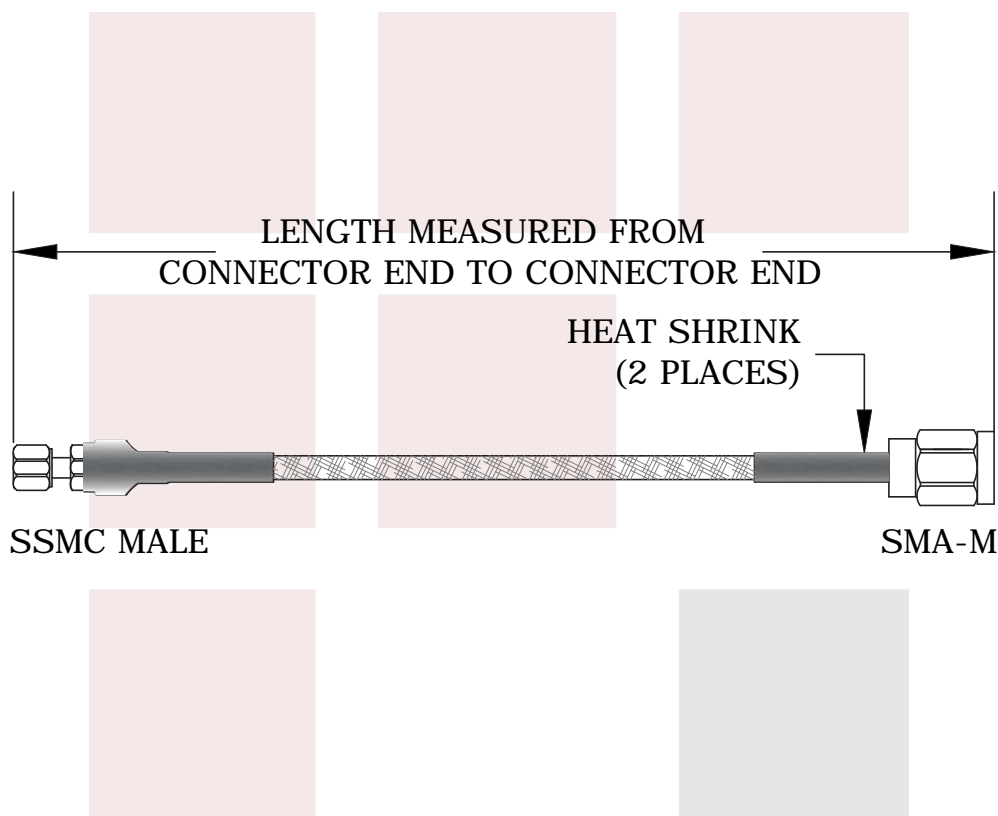

<b>FAIRVIEW MICROWAVE INC.</b> ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM		NOTES: 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL. 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME. 3. DIMENSIONS ARE IN INCHES [mm].			
TITLE SSMC Male to SMA Male Cable RG405 Type .086 Coax and RoHS	DWG NO <b>SCA28086</b>		CAGE CODE <b>3FKR5</b>		
	CAD FILE 101614	SHEET	SCALE N/A	SIZE A	5568