



SMA/M-RA - BNC/M FLEXIBLE CABLES 1GHZ RG316

SCB15256-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR: 1.5 @ < 1GHZ TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@ 1GHZ: 0.26 DB/FT
@ 2GHZ: 0.38 DB/FT
@ 3GHZ: 0.47 DB/FT

CONNECTORS:
BNC: BRASS
SMA torque 5-in-lbs
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

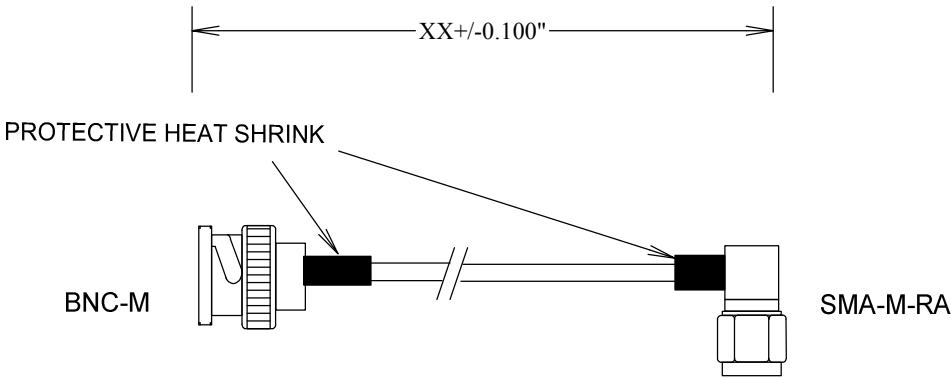

MEASUREMENTS BELOW ARE TYPICAL

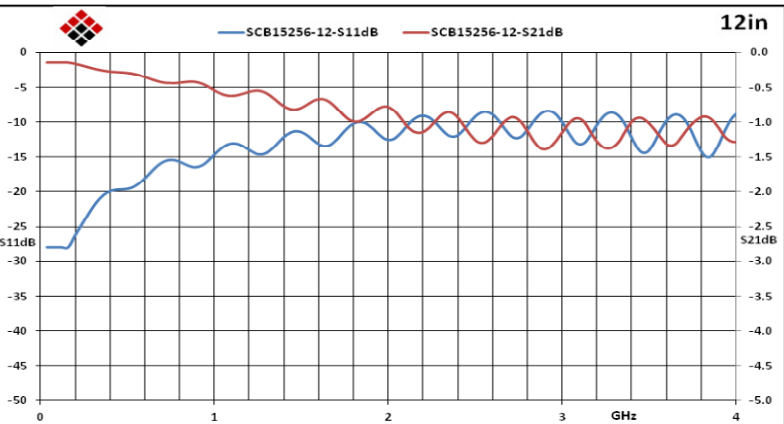

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-RA - BNC/M FLEXIBLE CABLES 1GHZ RG316

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15256-XX

REV

--

SCALE

SHEET

ALL DIMENSIONS IN inches(MM) Typical

