

N/M/RA - N/M/RA- FLEXIBLE CABLES 6GHZ LMR400

SCB15594-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 6GHZ TYPICAL


RAW CABLE: LMR400
TYPICAL LOSS (EXCLUDING CONNECTORS)
@1GHz: 0.041 DB/FT
@2GHz: 0.06DB/FT
@4Ghz: 0.087db/ft
@6GHz: 0.11 DB/FT

CONNECTORS: BRASS
CONTACTS Au PLATING
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

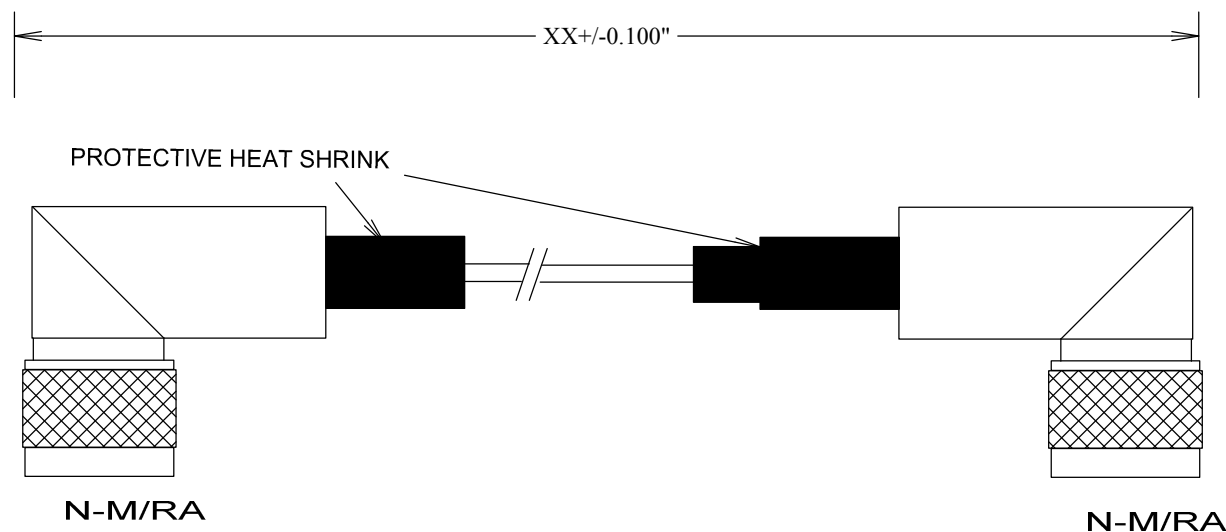

MEASUREMENTS BELOW ARE TYPICAL

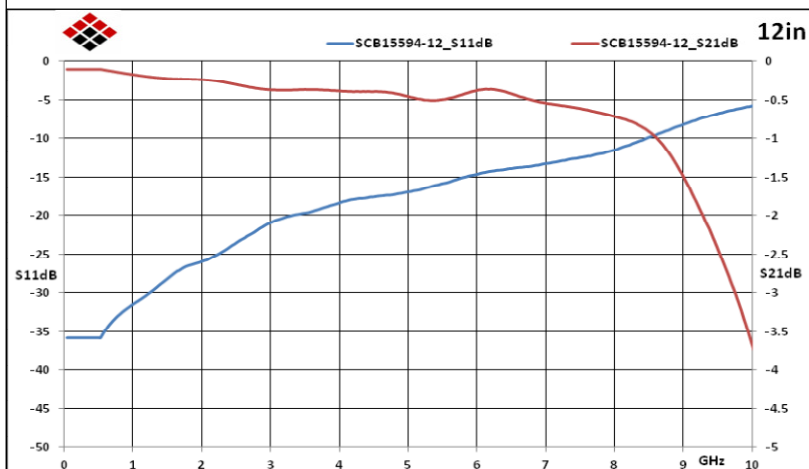

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

N/M/RA - N/M/RA- FLEXIBLE CABLES
6GHZ LMR400

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15594-XX

REV

--

SCALE

SHEET