

# N/M - N/M/RA- FLEXIBLE CABLES 6GHZ LMR240

SCB15670-XX


## SPECIFICATIONS

CABLE ASSEMBLY:  
VSWR:1.2:1 @< 6GHZ TYPICAL


RAW CABLE: LMR240  
TYPICAL LOSS (EXCLUDING CONNECTORS)  
@1GHz: 0.081 DB/FT  
@2GHz: 0.116 DB/FT  
@6GHz: 0.205 DB/FT

CONNECTORS: BRASS  
CONTACTS Au PLATING  
INTERFACE: MIL-STD-348A

OP TEMP: -55-110°C

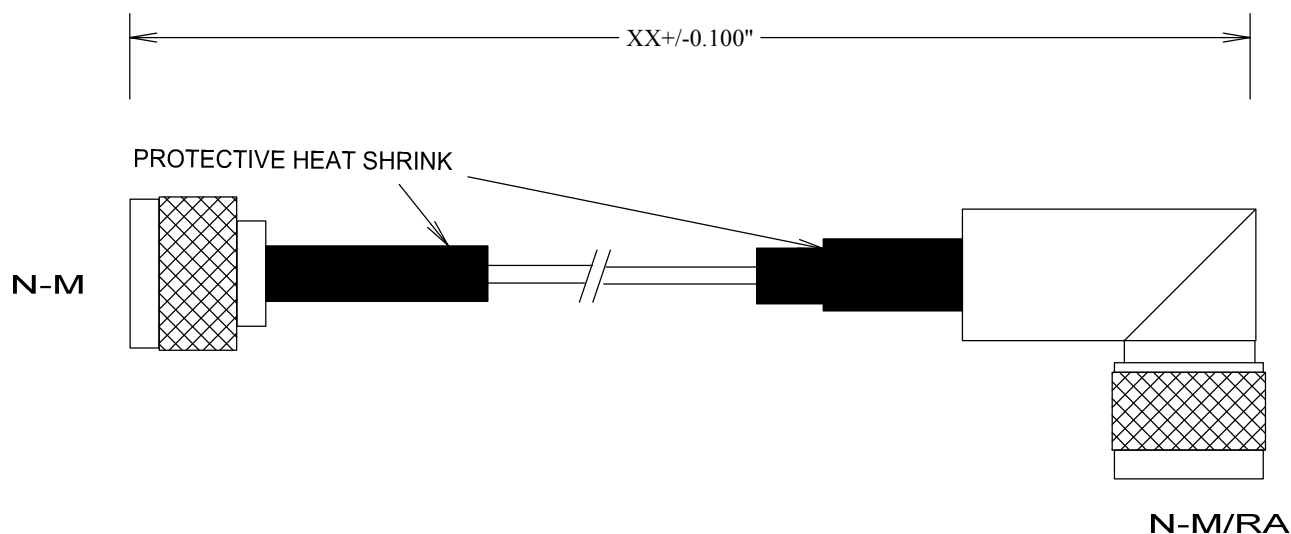

MEASUREMENTS BELOW ARE TYPICAL

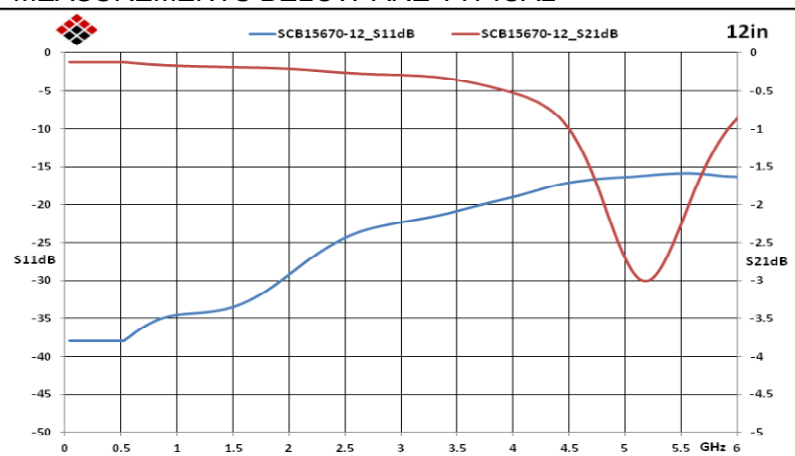

ALL DIMENSIONS IN inches(MM) Typical

**FAIRVIEW MICROWAVE INC.**

ALLEN, TX 75013 [WWW.FAIRVIEWMICROWAVE.COM](http://WWW.FAIRVIEWMICROWAVE.COM)

TITLE

N/M - N/M/RA- FLEXIBLE CABLES 6GHZ LMR240

SIZE

**A**

CAGE CODE

**3FKR5**

DWG NO

**SCB15670-XX**

REV

--

SCALE

SHEET