

SMA/F/BULKHEAD - SMA/F/BLKHD FLEXIBLE CABLES RG316

SCB15826-XX


SPECIFICATIONS

CABLE ASSEMBLY:
VSWR:1.2:1 @< 2GHZ TYPICAL


RAW CABLE: RG316
TYPICAL LOSS (EXCLUDING CONNECTORS)
@ 100MHZ: 0.08 DB/FT
@1GHz: 0.29 DB/FT
@3GHz: 0.54DB/FT
@5GHz: 0.62 DB/FT

CONNECTORS:
SMA: BRASS torque 5-in-lbs
CONTACTS Au PLATING 30μ
INTERFACE: MIL-STD-348A

TEMPERATURE: -55° to +110°C

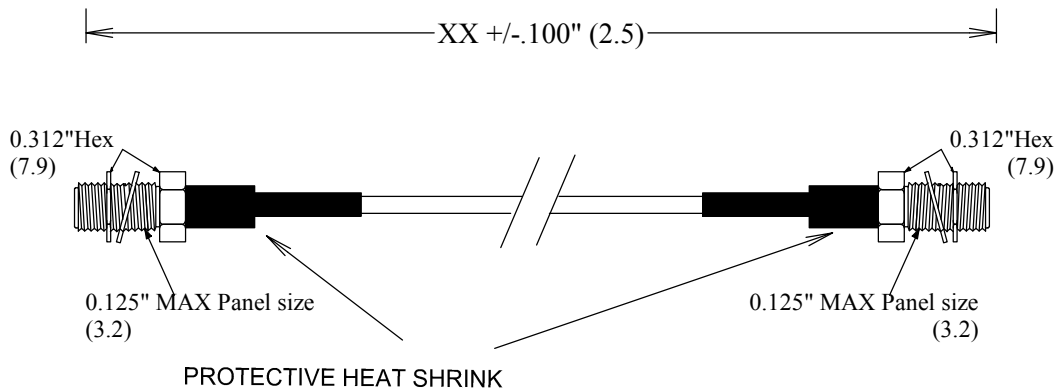

MEASUREMENTS BELOW ARE TYPICAL

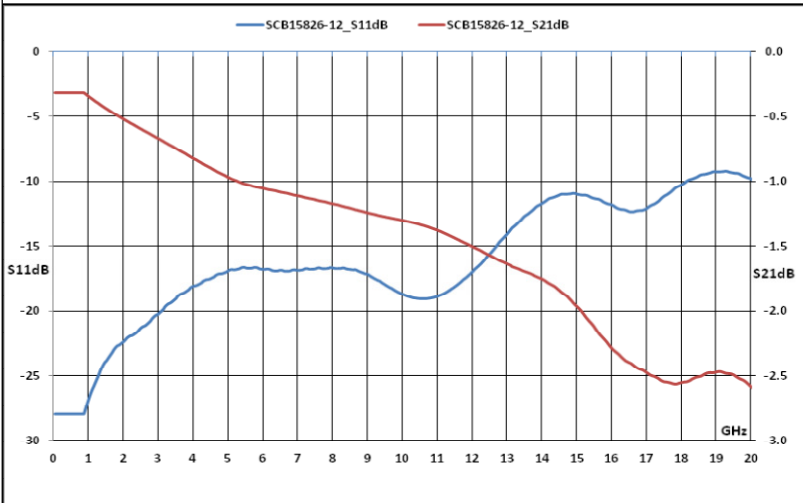

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

**SMA/F/BULKHEAD - SMA/F/BLKHD
FLEXIBLE CABLES RG316**

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15826-XX

REV

--

SCALE

SHEET