

SMA/M-N/M FLEXIBLE CABLES 6GHz LMR240

SCB15835-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @< 6GHz TYPICAL

RAW CABLE: LMR240

TYPICAL LOSS (EXCLUDING CONNECTORS)

@0.5GHz 0.06 dB/ft

@1GHz 0.08dB/ft

@2GHz 0.11dB/ft

@3GHz 0.14dB/ft

@6GHz 0.21dB/ft

CONNECTORS:

BRASS


CONTACTS Au PLATING

INTERFACE: MIL-STD-348A


SMA-CONNECTOR TORQUE 5-in-lbs

OP TEMP: -55-200°C

ROHS COMPLIANT

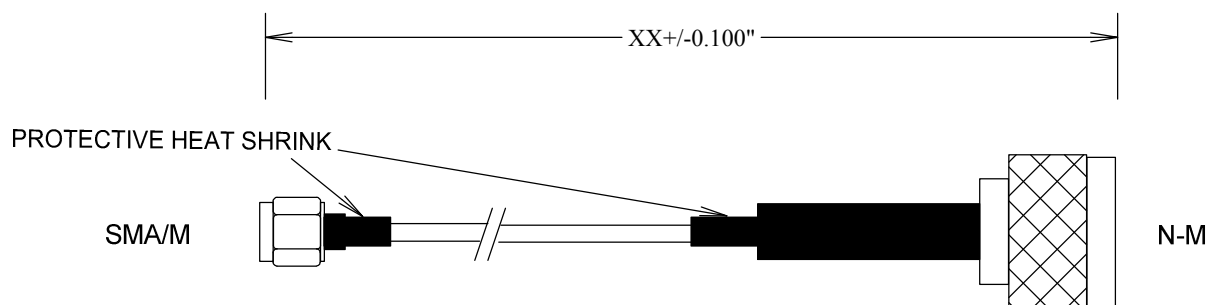

MEASUREMENTS BELOW ARE TYPICAL

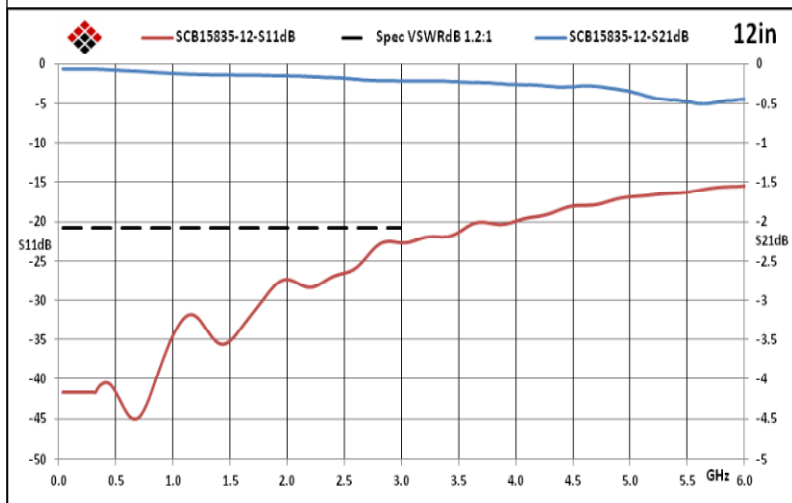

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-N/M FLEXIBLE CABLES 6GHz LMR240

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCB15835-XX

REV

--

SCALE

SHEET

ALL DIMENSIONS IN inches(MM) Typical