

SMA/M-N/M FLEXIBLE CABLES 18GHz HF086

SCF31086-XX

SPECIFICATIONS

CABLE ASSEMBLY:

VSWR:1.2:1 @< 18GHz TYPICAL

RAW CABLE: HF086

TYPICAL LOSS (EXCLUDING CONNECTORS)

@400MHz 0.14 dB/ft

@1GHz 0.23 dB/ft

@3GHz 0.39 dB/ft

@5GHz 0.52 dB/ft

@10GHz 0.8 dB/ft

@18GHz 1.1 dB/ft

CONNECTORS:

BRASS



CONTACTS Au PLATING

INTERFACE: MIL-STD-348A

SMA-CONNECTOR TORQUE 5-in-lbs

OP TEMP: -55 to+110°C

ROHS COMPLIANT

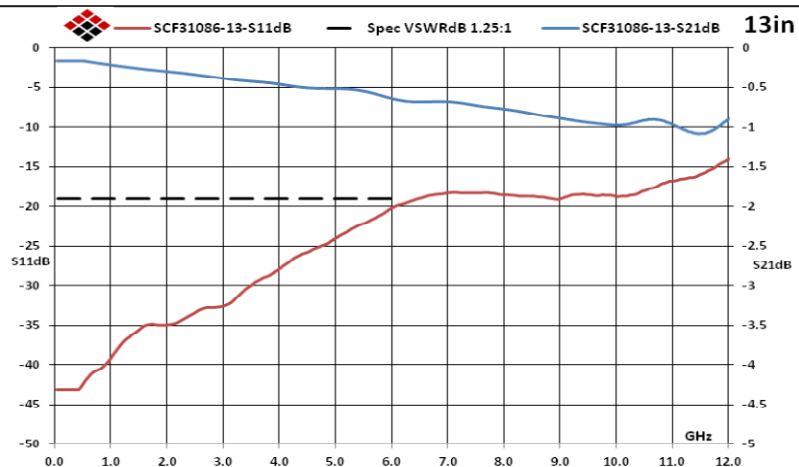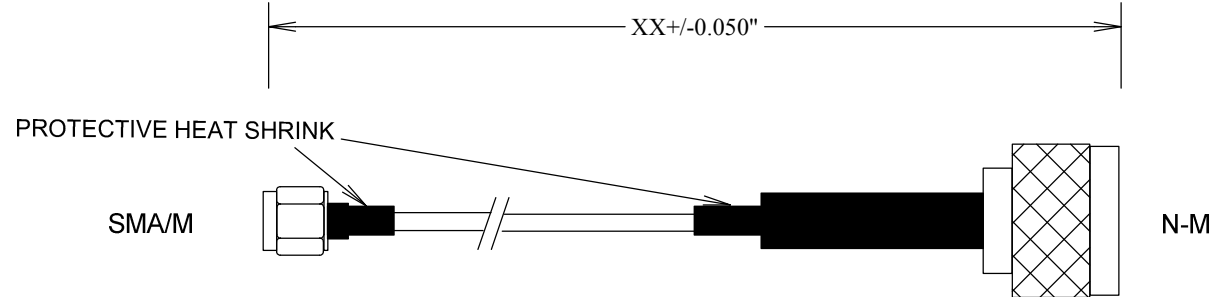

ALL DIMENSIONS IN inches(MM) Typical

FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

SMA/M-N/M FLEXIBLE CABLES 18GHz HF086

SIZE

A

CAGE CODE

3FKR5

DWG NO

SCF31086-XX

REV

--

SCALE

SHEET