

# MMCX-BNC ADAPTERS 6GHZ

SM3615

## SPECIFICATIONS

### ELECTRICAL

FREQUENCY: 0-6 GHZ

IMPEDANCE: 50 OHMS

VSWR: 1.2:1 MAX @ 0-2GHZ

1.35:1 MAX @ 2-6GHZ

### MECHANICAL

MATERIAL BODY: NICKEL PLATED BRASS

MATERIAL CONTACT MMCX: BeCu


MATERIAL CONTACT BNC: BRASS

CONTACT PLATING: Au PER MIL-G-45204


INSULATOR: TEFLON

INTERFACE: MIL-STD-348

MEASUREMENTS BELOW ARE TYPICAL

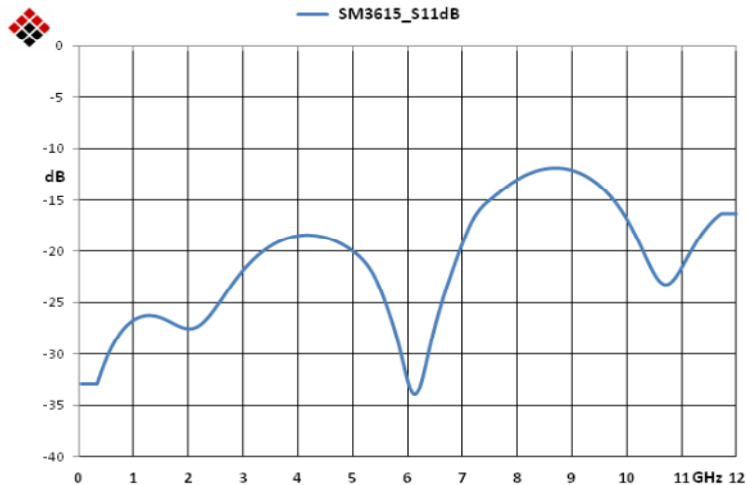

BNC-F

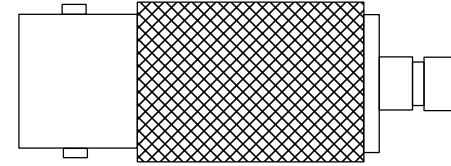

MMCX-P

0.45"  
(11.4)

1.20"  
(30.5)

ALL DIMENSIONS IN inches(MM) Typical

## FAIRVIEW MICROWAVE INC.

ALLEN, TX 75013 WWW.FAIRVIEWMICROWAVE.COM

TITLE

### MMCX-BNC ADAPTERS 6GHZ

SIZE	CAGE CODE	DWG NO	REV
A	3FKR5	SM3615	--
SCALE			SHEET